

Connection plate for aluminium profile

ACLPR

Right angled connection

- **Corner reinforcement**
- Connection of 2 aluminium profiles at a right angle
- Material:
Anodised aluminium



Info.

- Supplied without fixing kit (see button head screw **BHC8-16/SS/B** or **BHC8-20/SS** and slot nut **PRF-ECL-M8/SS**)

Anodised aluminium



Typical application

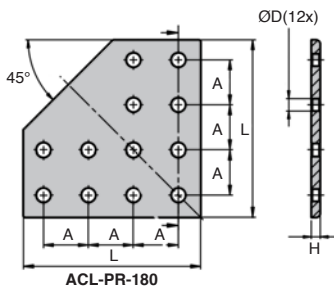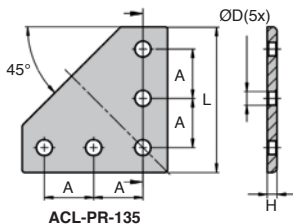

DISCOUNTS

Qty	1+	50+	100+
Disc. Net	-5%	On request	

Part N°	L	H	A	ØD	Weight (g)	Price each 1 to 49
ACL-PR-135	133	6	45	9	215	13,63 €
ACL-PR-180	178	6	45	9	435	22,16 €

All dimensions in mm

Altri prodotti...



Q6

Cuscinetto radiale a sfere, Acciaio



CLG1

Ingranaggio dritto in plastica stampata , Nylon stampato



CHTRP

Riduttore a rinvio angolare a L o a T, fino a 87,3Nm



PRF_ECL

Fissaggio, Dado quadrato con linguetta - Acciaio



VTAP

Vite a testa magnetica, Con rivestimento in gomma



BLHT50

Rinvio angolare a T, da 11.50 a 30 Nm



PO

Maniglia a ponte - Multi-settore, Foro cieco maschiato



PX

Riduttore a ruota e vite senza fine, Albero doppio in uscita per rid...



GBMf

Dado per vite a sfere, Dado flangiato a



HLC28

Rinvio angolare a dentatura spiroidale,



CLLCLLP

Perno serie lunga, Acciaio - serie lunga



RFK38B

Riduttore ipoide inox, fino a 200 Nm

Prodotti correlati



BHC

Vite a testa bombata BHC , Inox A2



PRF_ECL

Fissaggio, Dado quadrato con linguetta - Inox



ACL-PL

Elementi di giunzione, Piastra di fissaggio - 176x86 mm



ACL-PL

Elementi di giunzione, Piastra di fissaggio - 86x86 mm