

Connection plate for aluminium profile

ACLPR

Right angled connection

- **Corner reinforcement**
- Connection of 2 aluminium profiles at a right angle
- Material:
Anodised aluminium



Info.

- Supplied without fixing kit (see button head screw **BHC8-16/SS/B** or **BHC8-20/SS** and slot nut **PRF-ECL-M8/SS**)

Anodised aluminium



Typical application

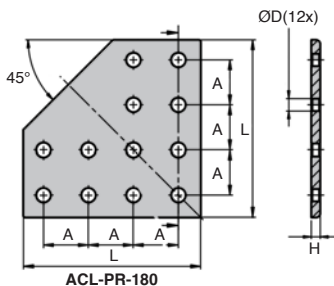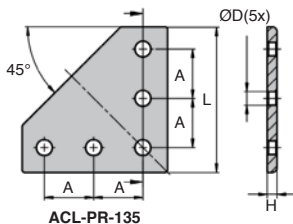

DISCOUNTS

Qty	1+	50+	100+
Disc. Net	-5%	On request	

Part N°	L	H	A	ØD	Weight (g)	Price each 1 to 49
ACL-PR-135	133	6	45	9	215	13,63 €
ACL-PR-180	178	6	45	9	435	22,16 €

All dimensions in mm

Altri prodotti...



CHMX_CHMDX

Albero per riduttore a ruota e vite senza fine CHMR e CHM, Albero se...



PLC_PLT

Magnete, Con foro centrale




SVR30

Martinetto a vite - Vite rotante, Con madrevite esterna



CHAL3

Cerniera piana, Alluminio

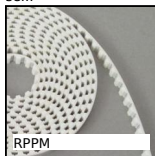

RPPM

Cinghia aperta al metro tipo RPP, RPP5 Poliuretano armatura in acciaio



CLB_M

Maniglia a ripresa, Zamak



TCLar

Tenditore per catena automatico, Con pattino largo



ZG0

Ingranaggio dritto in plastica, Plastica lavorata (delrin)




PTAF80-PAMF80

Piede fissabile con base lamiera Ø80, Ø



PSG255

Ingranaggio dritto di precisione, Inox 303

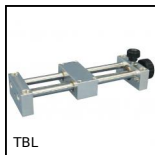

TBL

Mini tavola di posizionamento a vite



BEAB

Manopola, stella, anti-bacterial

Prodotti correlati



BHC

Vite a testa bombata BHC , Inox A2



PRF_ECL

Fissaggio, Dado quadrato con linguetta - Inox



ACL-PL

Elementi di giunzione, Piastra di fissaggio - 176x86 mm



ACL-PR

Elementi di giunzione, Collegamento a 90°