

Connection plate for aluminium profile

ACLPR

Right angled connection

- **Corner reinforcement**
- Connection of 2 aluminium profiles at a right angle
- Material:
Anodised aluminium



Info.

- Supplied without fixing kit (see button head screw **BHC8-16/SS/B** or **BHC8-20/SS** and slot nut **PRF-ECL-M8/SS**)

Anodised aluminium



Typical application

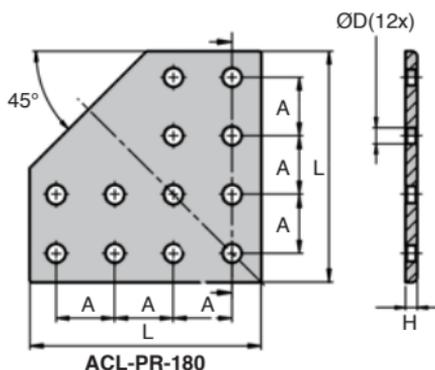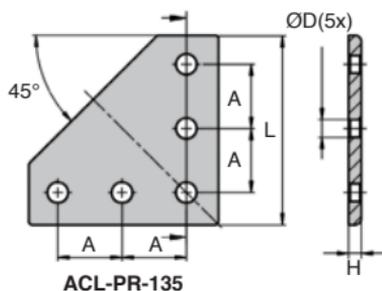

DISCOUNTS

Qty	1+	50+	100+
Disc. Net	-5%	On request	

Part N°	L	H	A	ØD	Weight (g)	Price each 1 to 49
ACL-PR-135	133	6	45	9	215	13,63 €
ACL-PR-180	178	6	45	9	435	22,16 €

All dimensions in mm

Altri prodotti...



FF20

Riduttore ad alberi paralleli, da 5.80 a 23 Nm



MHSC

Giunto flessibile a disco semplice, Disco semplice



J53

Riduttore coassiale a treni paralleli, da 0.27 a 0.90 - a treni para...



AT10-50ECO

Puleggia dentata di posizionamento tipo AT, Serie economica - AT10 a...



PR881

Ruota di rinvio, Serie 881



GLB

Piccolo Volano a 6 alette, Tecnopolimero - Ottone



RBGtc

Ruota girevole a foro centrale, Acciaio - gomma grigia - a doppio bl...



BUT

Accessori per pannello, Arresto per pannello



PRS30

Piede snodato tutto inox Ø30, Ø 30



PAT123

Piede snodato con base lamiera Ø123, Ø



Q4

Cuscinetto a doppia corona di sfere,



BLHT30

Rinvio angolare a T, da 1.65 a 4.40 Nm

Prodotti correlati



BHC

Vite a testa bombata BHC , Inox A2



PRF_ECL

Fissaggio, Dado quadrato con linguetta - Inox



ACL-PL

Elementi di giunzione, Piastra di fissaggio - 176x86 mm



ACL-PR

Elementi di giunzione, Collegamento a 90°