



Joint for aluminium profiles

Corner and variable angle hinge

ACLEAV ACLPV

- Components for creating angled joints
- Material

Corner : Cast aluminium

Hinge : chromed steel

Advantages

- Adjustable angle

Info

- No mounting screws supplied (see PRF-ECL-M8/screw FHC8 and CHC8)





ACL-EAV-45





ACL-PAV-130

NEW!

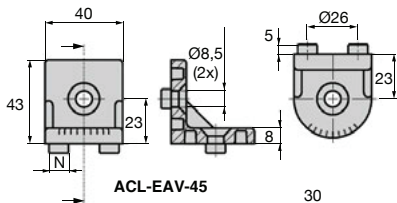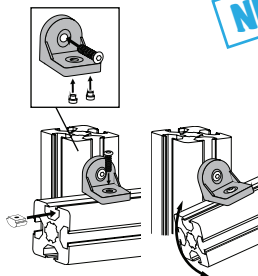

ACL-EAV-45

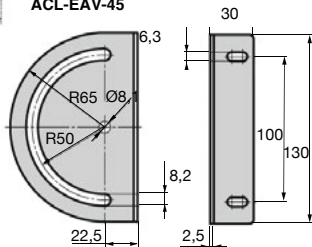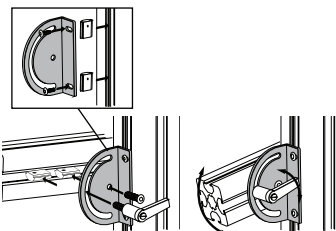

ACL-PAV-130

DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	Type	Screw size	N	Weight (g)	Price each 1 to 49
ACL-EAV-45	Corner	M8	8/10	44	3,64 €
ACL-PAV-130	Hinge	M8	-	221	6,75 €

Dimensions in mm

Altri prodotti...



BCTH

Pomello a fungo Hygienic Usit®, Con foro filettato e collare alto




SH0

Ingranaggio elicoidale ad assi paralleli, Acciaio 20NCD2



PRF_TOOL

Attrezzi, Chiave di montaggio

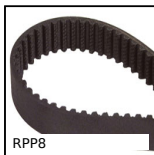

RPP8

Cinghia di trasmissione RPP, RPP8




RHTplss

Ruota alte temperature, fino a 200kg



PSG125

Ingranaggio dritto di precisione, Acciaio 20NCD2 cementato temprato

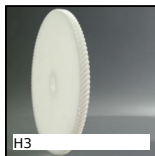


H3

Ingranaggio elicoidale ad assi incrociati a 90°, Plastica lavorata



CHAEss

Cerniera estetica, Inox

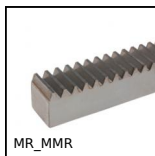

MR_MMR

Cremagliera sezione metrica, Acciaio



SH0

Ingranaggio elicoidale ad assi paralleli, Acciaio 20NCD2



GLT2-27

Guide telescopiche per montaggio in scanalatura,



PTAF100-PAMF100

Piede fissabile con base lamiera Ø100, Ø 100

Prodotti correlati



PRF4545

Profilato alluminio standard, 45 x 45 mm



PRF_ECL

Fissaggio, Dado quadrato con linguetta - Acciaio