



Joint for aluminium profiles

Corner and variable angle hinge

ACLEAV ACLPV

- Components for creating angled joints
- Material

Corner : Cast aluminium

Hinge : chromed steel

Advantages

- Adjustable angle

Info

- No mounting screws supplied
(see PRF-ECL-M8/screw FHC8 and CHC8)





ACL-EAV-45





ACL-PAV-130

NEW!

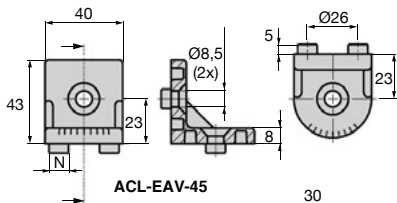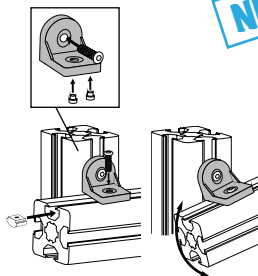

ACL-EAV-45

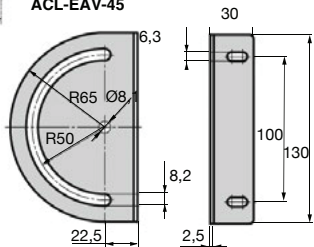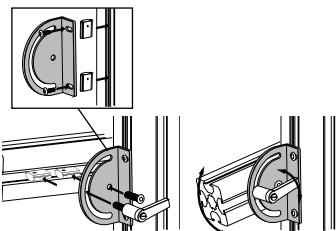

ACL-PAV-130

DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	Type	Screw size	N	Weight (g)	Price each 1 to 49
ACL-EAV-45	Corner	M8	8/10	44	3,64 €
ACL-PAV-130	Hinge	M8	-	221	6,75 €

Dimensions in mm

Altri prodotti...



GLP

Volantino a 6 lobi
filettato,
Tecnopolimero - Inox



BPM

Pressore a molla con
intaglio e puntale a
sfera, Inox 303



DOMI30

Slitta di regolazione
Domino 30, Slitta
DOMILINE 30



NCT_AT

Giunto di
collegamento, Ad
angolo variabile



ERT

Dado piastrina, Per
scanalatura a T



SH0

Ingranaggio elicoidale
ad assi paralleli,
Acciaio 20NCD2



UCP_PBT

Cuscinetto ritto
polimero inox,
polimero e inox



PCS_PA6

, 9.525mm (DIN
06B-1)



CLR

Staffa di montaggio
per molla a gas,
Staffa di montaggio



CMM

Testa a snodo
maschio DIN
ISO12240-4, Acciaio /



GE

Chiusura a leva,
Standard



SBS_L

Giunzione per catena
al metro, Falsa maglia
- inox

Prodotti correlati



PRF4545

Profilato alluminio
standard, 45 x 45 mm



PRF_ECL

Fissaggio, Dado
quadrato con
linguetta - Acciaio