

Adjustable foot for aluminium profile

ACLALF

- Mounting foot for aluminium structures that can be adjusted without tools
- Material:
Black fibreglass reinforced Nylon PA



Advantages

- Easy to assemble in central tapped hole of PRF4545 aluminium profile
- Supports up to 150 kg

NEW!



Ideal for workstations

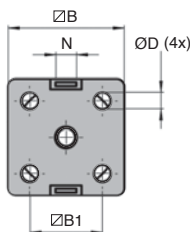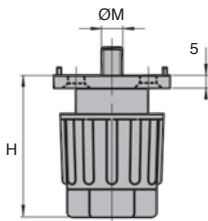

Assembly

DISCOUNTS

| | | | |
|-------|------|-----|------------|
| Qty | 1+ | 50+ | 100+ |
| Disc. | List | -5% | On request |

| Part number | B | H | N | ØM | B1 | ØD | Max load (kg) | Weight (g) | Price each 1 to 49 |
|----------------|----|-------|---|----|----|-----|---------------|------------|--------------------|
| ACL-ALF45-8-M8 | 45 | 45-65 | 8 | M8 | 28 | 6.5 | 150 | 80 | 5,25 € |

Dimensions in mm

Altri prodotti...



BLHB20

Rinvio angolare ad albero cavo, fino a 1.77 Nm



PM3

Coppia ruota e vite senza fine, Acciaio temprato



CLG2

Ingranaggio dritto in plastica stampata, Nylon stampato



BSP

Guida lineare di precisione, da 156 N a 980 N



PRF_GAL

Rotella per profilo alluminio, Rotella cava $\varnothing 12$




MHX

Manicotto esagonale maschiato, Esagonale - inox



CHA138

Cerniera ad avvitare, 138 gradi

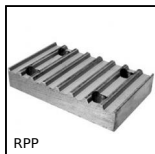

RPP

Piastra di giunzione per cinghia RPP, RPP8



MFB

Giunto a soffietto, Alluminio e bronzo - con vite a pressione



BOX-TOR-A

Valigetta di guarnizioni toriche in nitrile, 2.90 x 1.78mm



ZHG6

Ingranaggio dritto in plastica, Plastica lavorata (delrin)



DHX

Spina cilindrica filetto interno, estraibile DIN 7979D

Prodotti correlati



PRF4545_P

Profilato alluminio per camera bianca, 45 x 45 mm