

Adjustable foot for aluminium profile

ACLALF

- Mounting foot for aluminium structures that can be adjusted without tools
- Material:
Black fibreglass reinforced Nylon PA




Advantages

- Easy to assemble in central tapped hole of PRF4545 aluminium profile
- Supports up to 150 kg

NEW!



Ideal for workstations

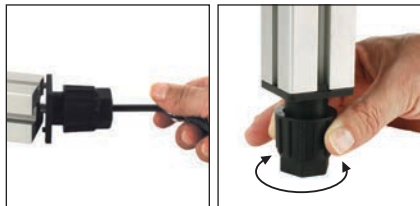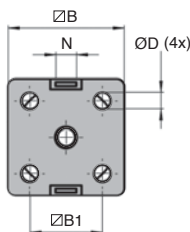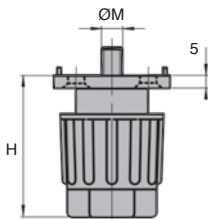

Assembly


DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	B	H	N	ØM	B1	ØD	Max load (kg)	Weight (g)	Price each 1 to 49
ACL-ALF45-8-M8	45	45-65	8	M8	28	6.5	150	80	5,25 €

Dimensions in mm

Altri prodotti...

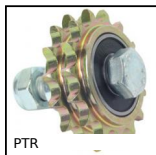

PTR

Pignone tendicatena,
Per applicazioni
correnti



RPCpl

Ruota girevole a
doppio bloccaggio,
Acciaio - poliammide



SSB

Ingranaggio conico
inox, 1:1



DER80

Motore inox AC
asincrono da 0,55 a
0,75kW, 0.55 a
0.75kW




PSG08S

Ingranaggio dritto di
precisione, Inox 303



PF45

Riduttore a ruota e
vite senza fine, fino a
40 Nm

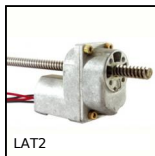

LAT2

Attuatore lineare a
motore 2A, 2 ampere



E60

Riduttore a rinvio
angolare, da 4.50 a
62 Nm



GE1006

Chiusura a leva
adattabile, Per
aggancio in gola



PSG125S

Ingranaggio dritto di
precisione, Inox 303



J52

Riduttore coassiale a
treni paralleli, da 0.27
a 0.90 - a treni para...



COA-COG

Staffa di montaggio
per molla a gas,
Staffa di montaggio
piana per f...

Prodotti correlati



PRF4545_P

Profilato alluminio per
camera bianca, 45 x
45 mm