



Magnetic stop for aluminium profiles

Shuts using magnetism

ACLAPA

- **Rapid closing mechanism for doors**
- **Material**
Black glass fibre reinforced nylon
Retaining force : 30-50N approx



Advantages

- Suitable for PRF aluminium profiles

Info

- No mounting screws supplied (see PRF-ECL-M6 and BHC6)
- Not sold individually, contact us for details

NEW!

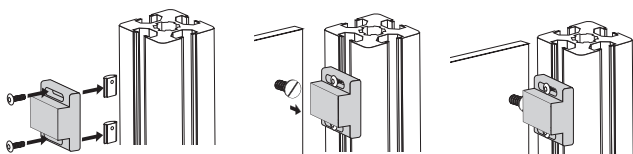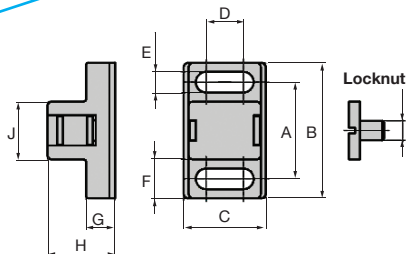

DISCOUNTS

Qty	1+	50+	100+
Disc. List	-5%		On request

Part number	DIN921 Locknut	A	B	C	D	E	F	G	H	J	Weight (g)	Price each 1 to 49
ACL-APA-20	M4x5	20	28	17	7,7	4,3	8	6	14	12	9	3,57 €
ACL-APA-30	M5x6	30	40	28	13,5	6,3	10,5	10	20	18,4	39	4,74 €

Dimensions in mm

Altri prodotti...



RAGb

Cylindrical brush track, For gentle conveying and handling



MRASSeco

Maglia rapida economica, Inox



SH0

Ingranaggio elicoidale ad assi paralleli, Plastica lavorata (delrin)



PR821

Ruota di rinvio, Serie 821 e 805




PFL

P-FLEX, Vite a pressione



EFSM

Cuscinetto a flangia quadrata Igubal®, Polimero

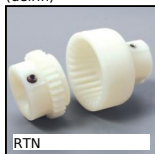

RTN

Giunto Bowex®, a dentatura bombata, Nylon



QNUP

Cuscinetto a singola corona di rulli cilindrici, Anello interno con ...



HSE-HSB

Distanziatore esagonale, Acciaio




HLC28

Rinvio angolare a dentatura spiroidale, Fino a 182Nm



PRF_ECL

Fissaggio, Dado quadrato con linguetta - Inox

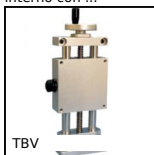

TBV

Tavola di posizionamento verticale manuale, 7kg

Prodotti correlati



PRF4545

Profilato alluminio standard, 45 x 45 mm



PRF_ECL

Fissaggio, Dado quadrato con linguetta - Acciaio



ACL-APB

Sistema di chiusura, Fermporta magnetico