



Magnetic stop for aluminium profiles

Shuts using magnetism

ACLAPA

- **Rapid closing mechanism for doors**
- **Material**
Black glass fibre reinforced nylon
Retaining force : 30-50N approx



Advantages

- Suitable for PRF aluminium profiles

Info

- No mounting screws supplied (see PRF-ECL-M6 and BHC6)
- Not sold individually, contact us for details

NEW!

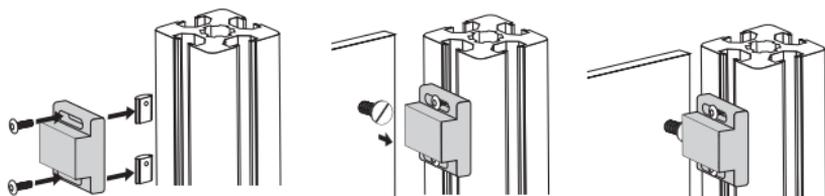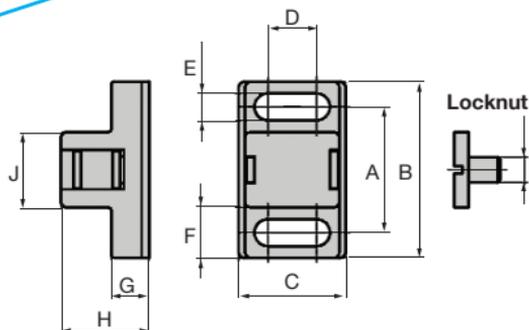

DISCOUNTS

Qty	1+	50+	100+
Disc. List	-5%	-5%	On request

Part number	DIN921 Locknut	A	B	C	D	E	F	G	H	J	Weight (g)	Price each 1 to 49
ACL-APA-20	M4x5	20	28	17	7,7	4,3	8	6	14	12	9	3,57 €
ACL-APA-30	M5x6	30	40	28	13,5	6,3	10,5	10	20	18,4	39	4,74 €

Dimensions in mm

Altri prodotti...



CLR

Staffa di montaggio per molla a gas, Staffa di montaggio per forcell...



CHINV2

Cerniera invisibile, Invisibile - Apertura fino a 125°



F7-P-AM

Visualizzatore multifunzione, Banda magnetica



H1

Ingranaggio elicoidale ad assi incrociati a 90°, Acciaio 20NCD2



PRF-SCREEN-1

Screen support, Basic support



KH

Manicotto a sfere, Leggera




SHW

Rondella semplice, Acciaio



UGH20

Unità di guida tipo H, Per martinetti Ø20

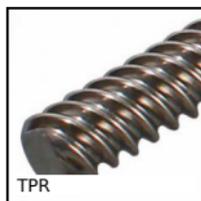

TPR

Madrevite a passo lungo, Madrevite solai fino a 40mm di corsa



CHN_CHNSS

Catena dritta a maglie lunghe, Inox



CHML63

Riduttore a ruota e vite senza fine, fino a 138 Nm - Con



DOMI120

Slitta di regolazione Domino 120, Slitta DOMILINE 120

Prodotti correlati



PRF4545

Profilato alluminio standard, 45 x 45 mm



PRF_ECL

Fissaggio, Dado quadrato con linguetta - Acciaio



ACL-APB

Sistema di chiusura, Fermporta magnetico