



Magnetic stop for aluminium profiles

Shuts using magnetism

ACLAPA

- **Rapid closing mechanism for doors**
- **Material**
Black glass fibre reinforced nylon
Retaining force : 30-50N approx



Advantages

- Suitable for PRF aluminium profiles

Info

- No mounting screws supplied (see PRF-ECL-M6 and BHC6)
- Not sold individually, contact us for details

NEW!

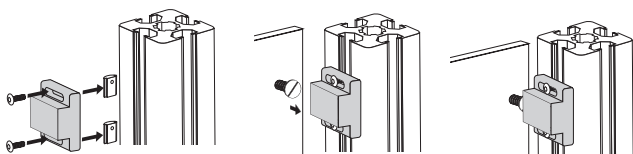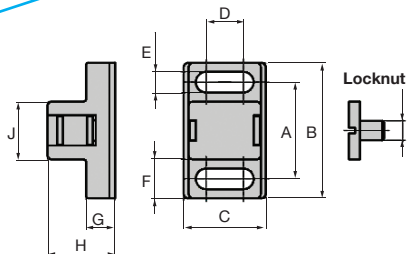

DISCOUNTS

Qty	1+	50+	100+
Disc. List	-5%		On request

Part number	DIN921 Locknut	A	B	C	D	E	F	G	H	J	Weight (g)	Price each 1 to 49
ACL-APA-20	M4x5	20	28	17	7,7	4,3	8	6	14	12	9	3,57 €
ACL-APA-30	M5x6	30	40	28	13,5	6,3	10,5	10	20	18,4	39	4,74 €

Dimensions in mm

Altri prodotti...



PRF_CH

Catena porta cavo,
Supplied in metre
lengths



PRF-P

Supporto piede, Per
piedi o ruote



VEL

Rotolo a strappo
fermacavi, cavi
elettrici e pneumatici



PTA150

Piede snodato con
base stampata Ø150,
40000N



PW_PWG3

Vite senza fine di
precisione, Acciaio



VB

Volantino a 6 lobi,
Duroplast - Inox



BABA

Perno autobloccante,
Acciaio



GE

Chiusura a leva,
Miniature



ACLLPP

Sistema di chiusura,
Chiusura a molla



PTA40

Piede snodato con
base stampata Ø40,
3000N



ATZYSS

Antivibrante elastico
inox sgolato, Inox



G-ECO

Ingranaggio dritto
acciaio - serie ECO,
Acciaio C45

Prodotti correlati



PRF4545

Profilato alluminio
standard, 45 x 45 mm



PRF_ECL

Fissaggio, Dado
quadrato con
linguetta - Acciaio



ACL-APB

Sistema di chiusura,
Fermporta magnetico