

# Closing mechanism for aluminium profiles **New**

## ACLBDB

## Double jointed stop

- **Rapid closing mechanism for doors**

- **Material**

Black glass fibre reinforced nylon  
Balls : stainless steel



### Advantages

- Suitable for use with  
PRF aluminium profiles

### Info

- No mounting screws supplied  
(see PRF-ECL-M6 and BHC6)

**NEW!**

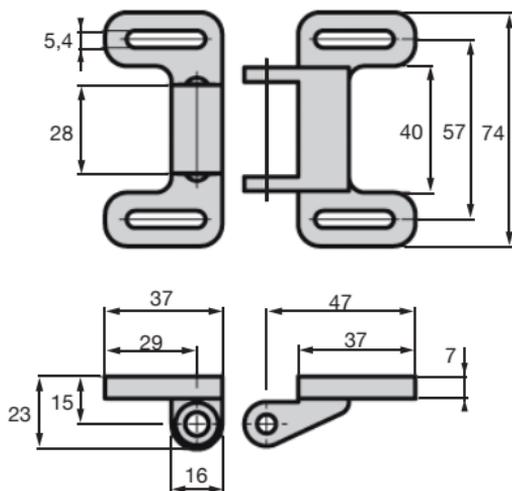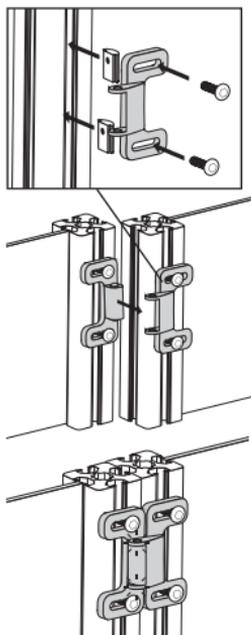

### DISCOUNTS

Qty	1+	50+	100+
Disc. List	-5%	On request	

Part number	Retaining force (N)	Weight (g)	Price each 1 to 49
ACL-BDB-25	25	38	5,35 €

Dimensions in mm

## Altri prodotti...



BG

Giunto Oldham, con vite a pressione



CHAupa



STRIP1000

Spazzola strip, Lunghezza 1m



PSPT

Manopola a pressione, PVC



GG3

Ingranaggio dritto rettificato, Acciaio trattato



CHAGC\_9SS

Cerniera a bandiera inox, A saldare



PRF4545

Profilato alluminio standard, 45 x 45 mm



RPB

Vite a ricircolo di sfere, Supporto



BRI

Accessori per pannello, Blocco di fissaggio



CHTRP

Riduttore a rinvio angolare a L o a T, fino a 9,1 Nm



SLB

Pistoncino a molla, inox



MSP38

Inserto con piastrina a incollare Masterplate®, Cilindrico Ø38 con...

## Prodotti correlati



PRF4545

Profilato alluminio standard, 45 x 45 mm



PRF\_ECL

Fissaggio, Dado quadrato con linguetta - Acciaio



ACL-APB

Sistema di chiusura, Fermoporta magnetico