



Detector support for aluminium profiles

Support for sensors from Ø6.5 to Ø12 ACLBMC



- **Sensor/Detector holder**
- **Material:**
Black glass fibre reinforced nylon

Advantages

- Suitable for use with PRF aluminium profiles
- Important: mounting accessories should be ordered separately
- Not sold individually, contact us for details



NEW!

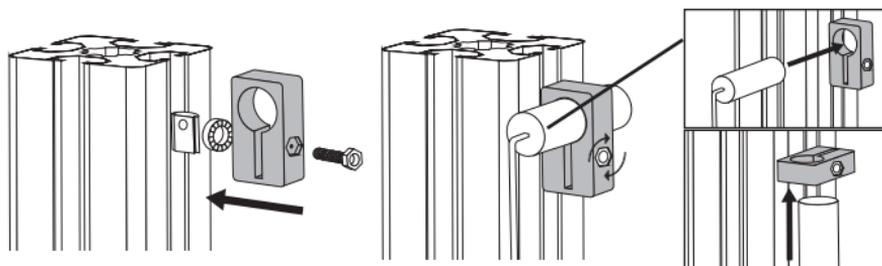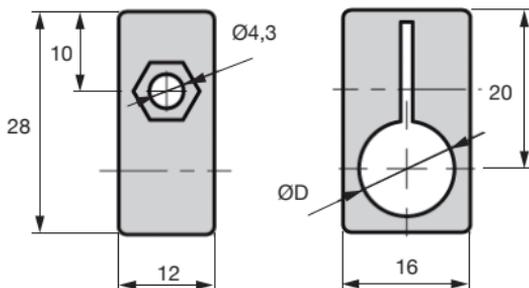

DISCOUNTS

Qty	1+	50+	100+
Disc. List	-5%		On request


Part number	Type	For screw	ØD	Weight (g)	Price each 1 to 49
ACL-BMC-6	Support	-	6,5	5	1,78 €
ACL-BMC-8	Support	-	8	4,5	1,78 €
ACL-BMC-12	Support	-	12	4	1,78 €
ACL-BMC-EF	Mounting accessories	M8		0,3	0,15 €

Dimensions in mm

Altri prodotti...



PT821
Pignone di trazione,
Serie 821 e 805

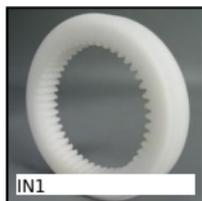

IN1
Ingranaggio interno,
Plastica lavorata
(delrin)



PSG125
Ingranaggio dritto di
precisione, Acciaio
20NCD2 cementato
temprato



GE14
Chiusura a leva, Con
porta-lucchetto



NK27
Guida mini Drylin® N,
Larghezza 27 mm



ACM_AZ
Aggancio per tirante
chiusura in gomma,
Aggancio



SSG0
Ingranaggio dritto
Inox, Inox 304L



ERF
Terminale rapido per
cavi, Terminale
filettato



RDE-B
Rondella di tenuta
Hygienic Usit®,



YG2
Ingranaggio dritto
PRESTAZIONE, Acciaio



GE1006
Chiusura a leva
adattabile, Per



PSG155
Ingranaggio dritto di
precisione, Inox 303

Prodotti correlati



PRF4545
Profilato alluminio
standard, 45 x 45 mm



PRF_ECL
Fissaggio, Dado
quadrato con
linguetta - Acciaio