



New

# Detector support for aluminium profiles

## Support for sensors from Ø6.5 to Ø12 ACLBMC



- **Sensor/Detector holder**
- **Material:**  
Black glass fibre reinforced nylon

### Advantages

- Suitable for use with PRF aluminium profiles
- Important: mounting accessories should be ordered separately
- Not sold individually, contact us for details



**NEW!**

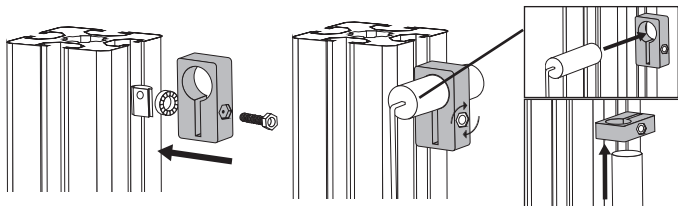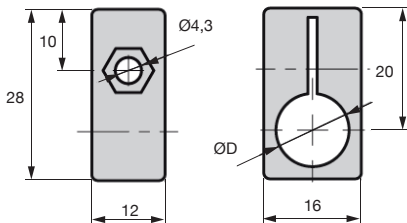

### DISCOUNTS

Qty	1+	50+	100+
Disc. List	-5%		On request

Part number	Type	For screw	ØD	Weight (g)	Price each 1 to 49
ACL-BMC-6	Support	-	6,5	5	1,78 €
ACL-BMC-8	Support	-	8	4,5	1,78 €
ACL-BMC-12	Support	-	12	4	1,78 €
ACL-BMC-EF	Mounting accessories	M8		0,3	0,15 €

Dimensions in mm

## Altri prodotti...



ACL-PL

Elementi di giunzione,  
Piastra di fissaggio -  
176x86 mm



AT5P\_AT10P

Piastra di giunzione  
per cinghia AT, AT10



NSB

Supporto standard per  
manicotto chiuso a  
sfere, Chiuso - Lungo



DIA

Pistoncino a molla,  
con anello



PTA150

Piede snodato con  
base stampata Ø150,  
Ø 150



SLVHlok

Bloccaggio a leva, A  
leva verticale / base  
orizzontale



VT

Limitatore di coppia  
ad attrito Vari-Tork®,  
0.53 a 1.32 Nm




BH01

Cuscinetto radiale  
flangiato, Montaggio :  
pressione e colla



RMSA

Deceleratore,  
Regolabile

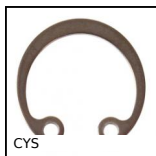


CYS

Anello di arresto  
interno DIN472,  
interno DIN 472



PRS30

Piede snodato tutto  
inox Ø30, Ø 30

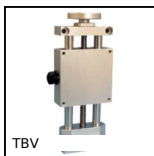

TBV

Tavola di  
posizionamento  
verticale manuale,  
3kg

## Prodotti correlati



PRF4545

Profilato alluminio  
standard, 45 x 45 mm



PRF\_ECL

Fissaggio, Dado  
quadrato con  
linguetta - Acciaio