

- Front mounting hinge for PRF4545 aluminium profiles
- Secured using DIN 7984 or DIN7380 M6 screws (not supplied)
- Material:  
Die cast aluminium  
Steel pin

**NEW!**




### Advantages

- Elongated holes permit correct positioning in case of deformation due to excessive weight or length



Elongated holes correct for errors in positioning or flexing

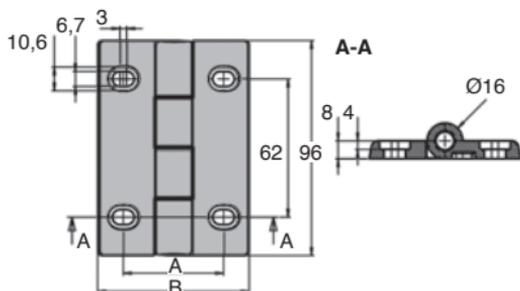

### DISCOUNTS

|       |      |     |            |
|-------|------|-----|------------|
| Qty   | 1+   | 50+ | 100+       |
| Disc. | List | -5% | On request |

| Part number   | A  | B  | Weight (g) | Price each 1 to 49 |
|---------------|----|----|------------|--------------------|
| ACL-CHAR78-96 | 50 | 78 | 169,5      | 11,23 €            |

Dimensions in mm

## Altri prodotti...



CLM  
Attacco per forcella,  
Corta acciaio



VPR  
Vite ad alette  
Hygienic Usit®, Inox



DB  
Ingranaggio conico -  
Acciaio 60C40, 2:1



LC  
Limitatore di coppia  
ad attrito, 30 a 240  
Nm



CHA60  
Cerniera,  
Rettangolare forata o  
con fori svasati



PTA80ssEB  
Piede snodato con  
base stampata Ø80,  
10000N



RGS  
Giunto senza gioco  
Rotex® GS, da 0.5 a  
190Nm



UCP\_SS  
Cuscinetto ritto tutto  
inox, Inox



SSG1\_304L  
Ingranaggio dritto  
Inox, Inox 304L



VT  
Limitatore di coppia  
ad attrito Vari-Tork®,  
0.53 a 1.32 Nm



T2  
Cinghia di  
posizionamento T,  
T2.5 Poliuretano



CHV  
Motovariatore  
meccanico, da 0,18 a  
1,5kW

## Prodotti correlati



PRF4545  
Profilato alluminio  
standard, 45 x 45 mm