

Floor anchor for aluminium profiles

ACLEFS

Right angled floor anchor



- For securing aluminium profiles to a floor

- Material :
Zamak

Advantages

- Suitable for use with PRF aluminium profiles
- Only for use with profiles wider than 40mm

NEW!

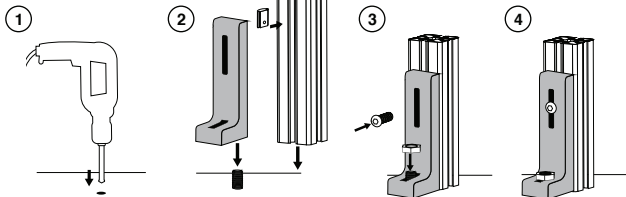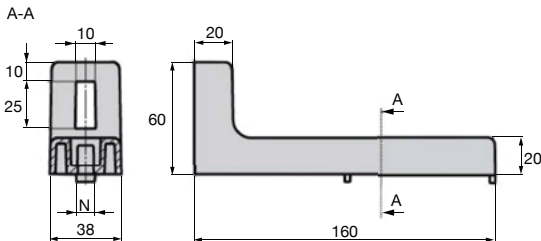

DISCOUNTS

Qty	1+	50+	100+
Disc. List	-5%	On request	

Part number	N	Weight (g)	Prix Uni. 1 à 49
ACL-EFS-160	8	110	10,57 €

Dimensions in mm



Floor anchor for aluminium profiles

Adjustable height floor anchor ACLEFS/A



- For securing aluminium profiles to a floor

Material:
Zamak

Advantages

- Adjustable
- Suitable for use with PRF aluminium profiles

NEW!

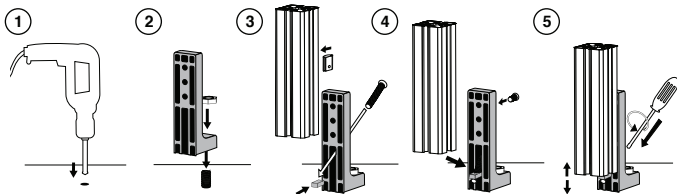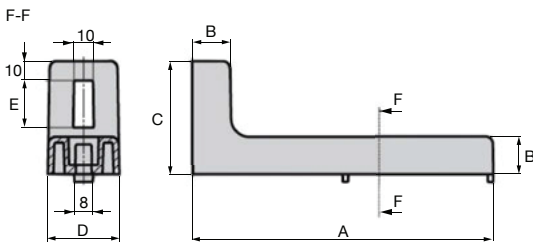

DISCOUNTS

Qty	1+	50+	100+
Disc. List	-5%		On request

Part number	Profile size (mm)	A	B	C	D	E	Max height	Weight (g)	Price each 1 to 49
ACL-EFS-120/A	30 min	120	15	45	28	19	52	88	11,83 €
ACL-EFS-160/A	40 min	160	20	60	38	29	72	120	16,34 €

Dimensions in mm

Altri prodotti...



S_2RS
Cuscinetto radiale a sfere, Inox



BOX-TOR-A
Valigetta di guarnizioni toriche in nitrile, 2.90 x 1.78mm a 28.17 x...



AT10-32ECO
Puleggia dentata di posizionamento tipo AT, Serie economica - AT10 a...



PW_PWG05
Vite senza fine di precisione, Acciaio




PSG125S
Ingranaggio dritto di precisione, Inox 316




RFK48C
Riduttore ipoidi inox, fino a 350 Nm



SDG
Supporto con tirante ad occhio, Plastica

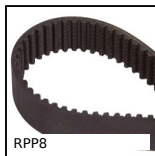

RPP8
Cinghia di trasmissione RPP, RPP8

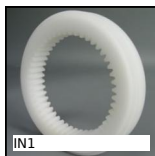

IN1
Ingranaggio interno, Plastica lavorata (delrin)



DOG319
Motoriduttore DC 12V e 24V DC, da 4 a 9 Nm



MAX26
Motoriduttore DC 12V e 24V DC, da 0,075 a 0,6Nm



FF20
Riduttore ad alberi paralleli, da 5.80 a 23 Nm

Prodotti correlati



PRF4545
Profilato alluminio standard, 45 x 45 mm