

# Floor anchor for aluminium profiles

## ACLEFS

## Right angled floor anchor



- For securing aluminium profiles to a floor

- Material :  
Zamak

### Advantages

- Suitable for use with PRF aluminium profiles
- Only for use with profiles wider than 40mm

**NEW!**

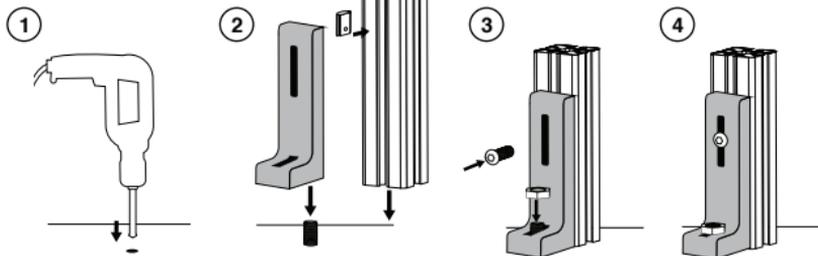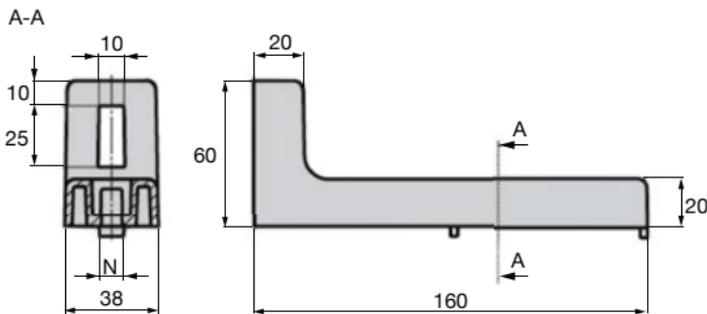

### DISCOUNTS

Qty	1+	50+	100+
Disc. List	-5%	On request	

Part number	N	Weight (g)	Prix Uni. 1 à 49
ACL-EFS-160	8	110	10,57 €

Dimensions in mm



# Floor anchor for aluminium profiles

## Adjustable height floor anchor ACLEFS/A



- For securing aluminium profiles to a floor

Material:  
Zamak

### Advantages

- Adjustable
- Suitable for use with PRF aluminium profiles

**NEW!**

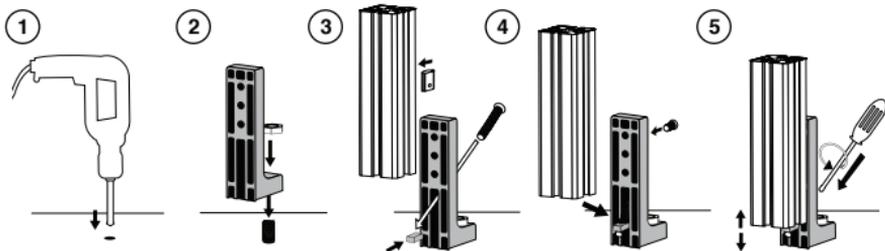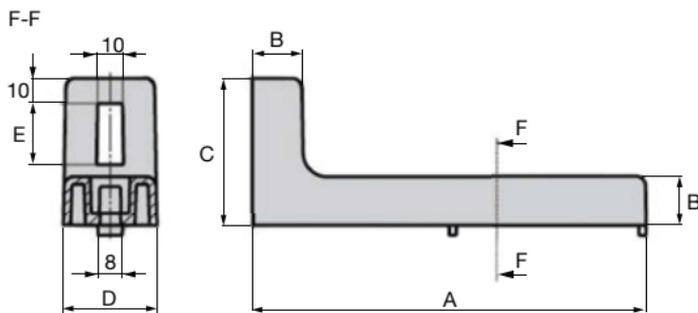

### DISCOUNTS

Qty	1+	50+	100+
Disc. List	-5%		On request

Part number	Profile size (mm)	A	B	C	D	E	Max height	Weight (g)	Price each 1 to 49
ACL-EFS-120/A	30 min	120	15	45	28	19	52	88	11,83 €
ACL-EFS-160/A	40 min	160	20	60	38	29	72	120	16,34 €

Dimensions in mm

## Altri prodotti...



SH0

Ingranaggio elicoidale ad assi paralleli, Acciaio 20NCD2



UTKswcr

Guida lineare Utilitrack®, Carrello a rotelle acciaio



BPM-Z

Pressore a molla con intaglio e puntale a sfera, Corpo plastica + sf...



MSP19

Inserto con piastrina a incollare Masterplate®, Cilindrico con dado



BPLE

Sfera portante a incastro, Leggero



BEAS

Manopola, stella, antistatico



VBFP

Volantino a 6 lobi - boccia passante, Duroplast - Ottone



PW\_PWG2

Vite senza fine di precisione, Acciaio



LINK64

Motoriduttore AC sincrono, da 1.3 a 6Nm



PTAF80-PAMF80

Piede fissabile con base lamiera Ø80, Ø 80



P20

Riduttore a ruota e vite senza fine, fino a 5 Nm



T5courroie

Cinghia di posizionamento T, T5 Poliuretano armatura in acciaio

## Prodotti correlati



PRF4545

Profilato alluminio standard, 45 x 45 mm