



Roller block for aluminium profiles

Create your own roller track

ACLERP

- Roller block for PRF aluminium profiles
- Materials
Black glass fibre reinforced nylon
Rollers : POM
- Exists in 2 versions,
with and without guide
- Max load : 100N each

Advantages

- Click to install






ACL-ERP-SG



ACL-ERP-AG

NEW!

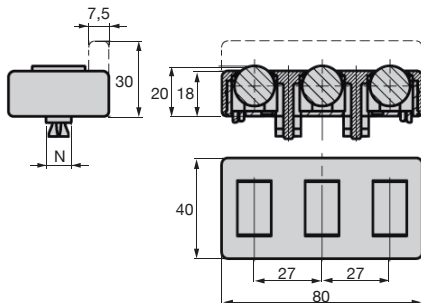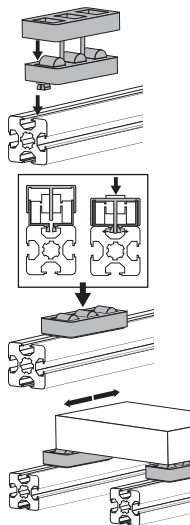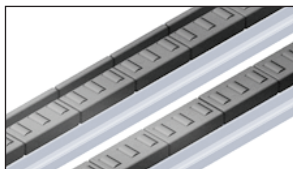

DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	Version	N	Weight (g)	Price each 1 to 49
ACL-ERP-SG	Without guide rail	8-10	43	3,82 €
ACL-ERP-AG	With guide rail	8-10	48	4,33 €

Dimensions in mm

Altri prodotti...



MET

Cuscinetto cilindrico ,
Self-lubricating
sintered bronze



M1

Coppia ruota e vite
senza fine , Acciaio
temprato



MDB_MTB

Ingranaggio conico in
plastica stampata ,
3:1



GLB

Piccolo volano a 6
alette, Tecnopolimero
- Inox



M0

Coppia ruota e vite
senza fine, Bronzo



AT5P_AT10P

Piastra di giunzione
per cinghia AT, AT10



PRS100

Piede snodabile tutto
inox Ø100, Ø 100



TSRTC

Stem support for
caster, For swivel
caster with central
hole



BHEX

Tappo di protezione
esagonale,
Tecnopolimero nero



BAG0

Anello di bloccaggio,
Inox



NT63

Riduttore coassiale a
treni paralleli, da 8 to
20 Nm - a treni



BLHB60

Rinvio angolare ad
albero cavo, fino a 70
Nm

Prodotti correlati



PRF4545

Profilato alluminio
standard, 45 x 45 mm