



Roller block for aluminium profiles

Create your own roller track

ACLERP

- Roller block for PRF aluminium profiles
- Materials
Black glass fibre reinforced nylon
Rollers : POM
- Exists in 2 versions,
with and without guide
- Max load : 100N each

Advantages

- Click to install





ACL-ERP-SG



ACL-ERP-AG

NEW!

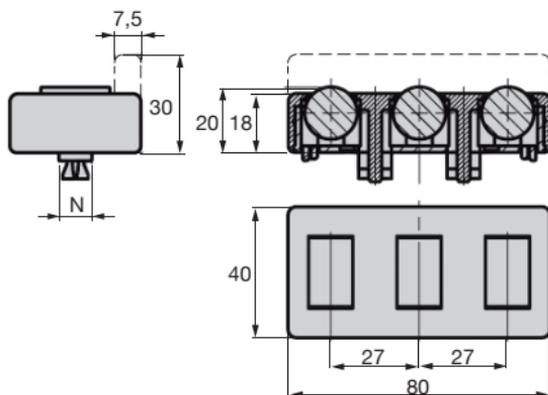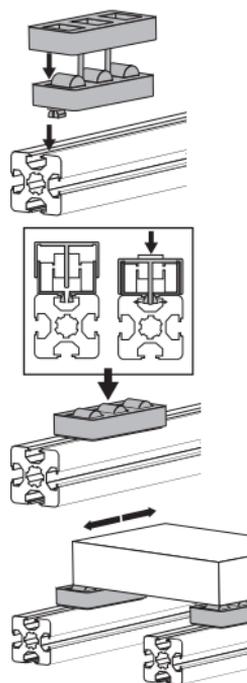

DISCOUNTS

Qty	1+	50+	100+
Disc.	List	-5%	On request

Part number	Version	N	Weight (g)	Price each 1 to 49
ACL-ERP-SG	Without guide rail	8-10	43	3,82 €
ACL-ERP-AG	With guide rail	8-10	48	4,33 €

Dimensions in mm

Altri prodotti...



H1

Ingranaggio elicoidale ad assi incrociati a 90°, Acciaio 20NCD2




RVM14

Riduttore manuale, A ruota e vite senza fine



SHNbr

Dado esagonale - DIN934, Ottone

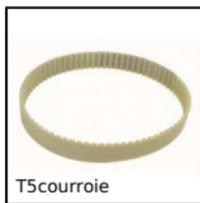

T5courroie

Cinghia di posizionamento T, T5 Poliuretano armatura in acciaio



PO

Maniglia a ponte - Multi-settore, Foro liscio



PTA150

Piede snodato con base stampata Ø150, 40000N



TBD

Tavola di posizionamento a passo inverso manuale, 2kg



VP

Volantino a 6 lobi, Duroplast - Acciaio



BLHT20

Rinvio angolare a T, da 0.66 a 1.77 Nm



EIM

Cavallotto Inox, Inox



TPR

Madrevite a passo lungo, Madrevite sola fino a 40mm di corsa



RJA00_02

Guarnizione in gomma, Da agganciare

Prodotti correlati



PRF4545

Profilato alluminio standard, 45 x 45 mm