



Latch for aluminium profiles

Spring operated latch

ACLLPP

- Spring operated latch for aluminium profiles

- Material

Body : Zamak

Handle : Black nylon

Nut : Stainless steel

Advantages





- Suitable for PRF aluminium profiles

- Mounts in any position

Info

- No mounting screws supplied
(see PRF-ECL-M6 and BHC6)

NEW!

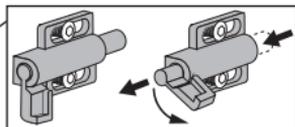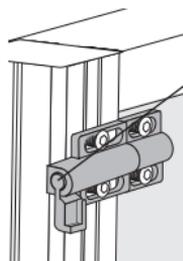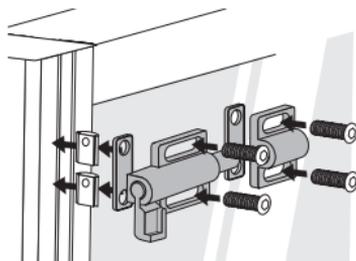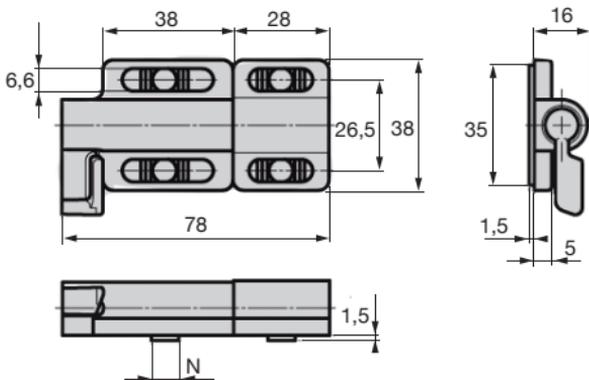

DISCOUNTS

Qty	1+	50+	100+
Disc. List	-5%		On request

Part number	N	Weight (g)	Price each 1 to 49
ACL-LPP-78	8-10	120	15,30 €

Dimensions in mm

Altri prodotti...



DIV_SS

Pistoncino a molla,
Bloccabile - Inox



BLHT70

Rinvio angolare a T,
da 26 a 128 Nm



ACLEPP

Angolare, 4 fori



GAC

Chiusura a leva con
serratura, Riscontro
grezzo



NK40

Guida mini Drylin® N,
Larghezza 40 mm



WJUM20

Pattino Drylin® W,
Pattino



ADSR

Giunto senza gioco
Gerwah®, da 12.5 a
525Nm



EV

Terminale rapido inox
per cavi,



EBM

Cavallotto in acciaio,
Acciaio



WW16

Carrello Drylin® W,
Carrello



SH4

Ingranaggio elicoidale
ad assi paralleli,
Acciaio 20NCD2



VDSQ

Bloccaggio scorrevole
per la regolazione,
Bloccaggio rapido per
prof...

Prodotti correlati



PRF4545

Profilato alluminio
standard, 45 x 45 mm



PRF_ECL

Fissaggio, Dado
quadrato con
linguetta - Acciaio