



Latch for aluminium profiles

Spring operated latch

ACLLPP

- Spring operated latch for aluminium profiles

- Material

Body : Zamak

Handle : Black nylon

Nut : Stainless steel

Advantages

 



- Suitable for PRF aluminium profiles

- Mounts in any position

Info

- No mounting screws supplied (see PRF-ECL-M6 and BHC6)

NEW!

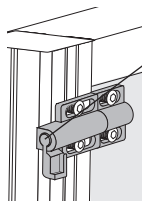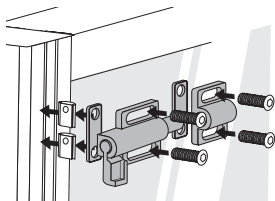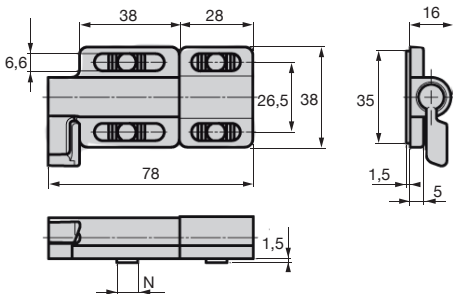

DISCOUNTS

Qty	1+	50+	100+
Disc. List	-5%		On request

Part number	N	Weight (g)	Price each 1 to 49
ACL-LPP-78	8-10	120	15,30 €

Dimensions in mm

Altri prodotti...



ERC
Terminale rapido per
cavi, A forcella



M0
Vite senza fine ,
Acciaio non temprato



ES
Support base (tripod),
Plastic



FHCSS
Vite a testa svasata
piana, Inox A2 - DIN
7991



SVR5
Martinetto a vite - Vite
rotante, Con
madrevite esterna



Q6
Cuscinetto radiale a
sfere, Acciaio



LSAG
Albero scanalato a
sfere, Carello - da 514
N a 15386 N



H0
Ingranaggio elicoidale
ad assi incrociati a
90°, Acciaio 20NCD2



EPRC
Dado cilindrico a
passo lungo, Dado



PCF4
Supporto antivibrante
cabina conico, Piastra



PPS
Anello di
sollevamento, Gancio



PM4
Vite senza fine,
Acciaio non temprato

Prodotti correlati



PRF4545
Profilato alluminio
standard, 45 x 45 mm



PRF_ECL
Fissaggio, Dado
quadrato con
linguetta - Acciaio