

# Fastening pin with ring


## AFA

## Steel


- **Ball pin**
- Quick and easy assembly of workpieces and other elements
- Double shear force (F) = S x τ<sub>AB</sub> max
- Materials:
  - Body - Chromed steel
  - Ring - Stainless steel

### Advantages

- These fastening pins with rings are an economic alternative to interlocking safety fasteners.
- They are easier to use and cheaper than a BAB ball pin but offer a lower level of safety

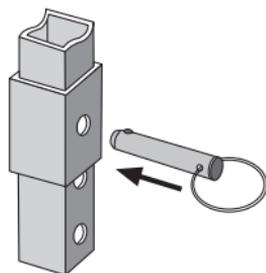

Typical application

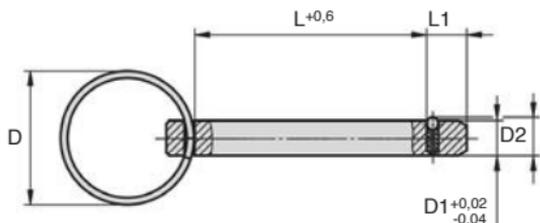


### DISCOUNTS

Qty	1+	6+	10+	25+
Disc.	List	-5%	-10%	On request

Part number	ØD	ØD1	ØD2	L	L1	Double shear strength (kN)	Stock*	Price each
								1 to 5
AFA6-15	23	6	6,5	15	7	22	✓	6,40 €
AFA6-20	23	6	6,5	20	7	22	-	6,53 €
AFA6-30	23	6	6,5	30	7	22	✓	6,69 €
AFA6-40	23	6	6,5	40	7	22	✓	6,87 €
AFA8-30	28	8	8,8	30	8	28	✓	6,69 €
AFA8-40	28	8	8,8	40	8	28	✓	6,87 €
AFA8-50	28	8	8,8	50	8	28	✓	7,10 €

Dimensions in mm

## Altri prodotti...

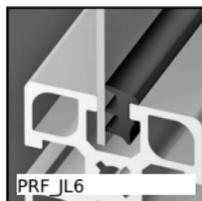

Panel accessories,  
Guarnizione - Ø 6mm



Ingranaggio dritto di  
precisione, Inox 316



Simple support base  
(bipod), Plastic



Volantino con razze e  
impugnatura girevole,  
Alluminio



Attacco per forcella,  
Corta acciaio



Ingranaggio conico in  
plastica, 2:1



Pistoncino a molla,  
Con flangia di  
fissaggio orizzontale



Ingranaggio elicoidale  
ad assi paralleli,  
Acciaio 20NCD2



Chiavetta  
rettangolare , Inox



Riduttore a ruota e  
vite senza fine, fino a  
40 Nm



Riduttore a rinvio  
angolare, da 0.40 a  
2.53 Nm



Chiavistello con perno  
prismatico, Lucchetto  
a molla

## Prodotti correlati



Perno di fissaggio, con  
chiusura a scatto



Copiglia a scatto, A  
scatto



Copiglia per tubo, Clip  
per tubo



Perno autobloccante a  
sfere, Inox temprato