

Fastening pin with ring


AFA

Steel


- **Ball pin**
- Quick and easy assembly of workpieces and other elements
- Double shear force (F) = S x τ_{AB} max
- Materials:
 - Body - Chromed steel
 - Ring - Stainless steel

Advantages

- These fastening pins with rings are an economic alternative to interlocking safety fasteners.
- They are easier to use and cheaper than a BAB ball pin but offer a lower level of safety

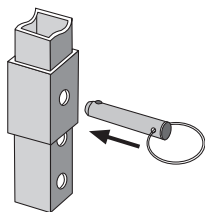

Typical application

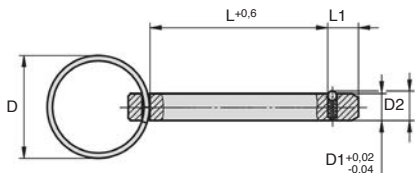

DISCOUNTS

Qty	1+	6+	10+	25+
Disc.	List	-5%	-10%	On request

Part number	ØD	ØD1	ØD2	L	L1	Double shear strength (kN)	Stock*	Price each
								1 to 5
AFA6-15	23	6	6,5	15	7	22	✓	6,40 €
AFA6-20	23	6	6,5	20	7	22	-	6,53 €
AFA6-30	23	6	6,5	30	7	22	✓	6,69 €
AFA6-40	23	6	6,5	40	7	22	✓	6,87 €
AFA8-30	28	8	8,8	30	8	28	✓	6,69 €
AFA8-40	28	8	8,8	40	8	28	✓	6,87 €
AFA8-50	28	8	8,8	50	8	28	✓	7,10 €


Dimensions in mm

Altri prodotti...



CHM63

Riduttore a ruota e vite senza fine, fino a 196 Nm

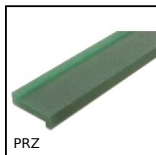

PRZ

Profilo supporto per catena, Profilo a Z da apposare




LVT

Mini martinetto motorizzato 1A, 1 ampere



BLH50

Rinvio angolare a L, da 7.70 a 20 Nm

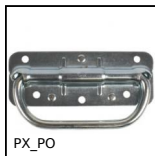

PX_PO

Maniglia - movimentazione manuale, con piastra posteriore



WTM

Rondella per serraggio - DIN6340, Acciaio



PSG085

Ingranaggio dritto di precisione, Inox 303



FUSS

Ghiera autofrenante per cuscinetto, Ghiera autofrenante - rondella i...



G4-ECO

Ingranaggio dritto acciaio - serie ECO,



FBL4004_K32

Spazzola al metro, Polipropilene nero



APB_T

Perno di fissaggio per morsetti, Maschiato



PRF3232

Profilato alluminio standard, 32 x 32 mm

Prodotti correlati



AFSE

Perno di fissaggio, con chiusura a scatto



GCA

Copiglia a scatto, A scatto



GCT

Copiglia per tubo, Clip per tubo



BAB

Perno autobloccante a sfere, Inox temprato