

# Fastening pin with ring


## AFA

## Steel


- **Ball pin**
- Quick and easy assembly of workpieces and other elements
- Double shear force (F) = S x τ<sub>AB</sub> max
- Materials:
  - Body - Chromed steel
  - Ring - Stainless steel

### Advantages

- These fastening pins with rings are an economic alternative to interlocking safety fasteners.
- They are easier to use and cheaper than a BAB ball pin but offer a lower level of safety

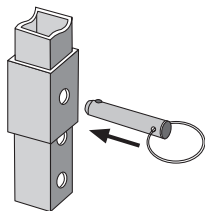

Typical application

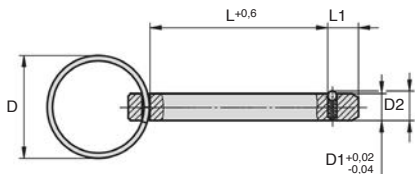

### DISCOUNTS

Qty	1+	6+	10+	25+
Disc.	List	-5%	-10%	On request

Part number	ØD	ØD1	ØD2	L	L1	Double shear strength (kN)	Stock*	Price each
								1 to 5
AFA6-15	23	6	6,5	15	7	22	✓	6,40 €
AFA6-20	23	6	6,5	20	7	22	-	6,53 €
AFA6-30	23	6	6,5	30	7	22	✓	6,69 €
AFA6-40	23	6	6,5	40	7	22	✓	6,87 €
AFA8-30	28	8	8,8	30	8	28	✓	6,69 €
AFA8-40	28	8	8,8	40	8	28	✓	6,87 €
AFA8-50	28	8	8,8	50	8	28	✓	7,10 €


Dimensions in mm

## Altri prodotti...




CLLCLLP

Forcella serie lunga,  
Lunga acciaio

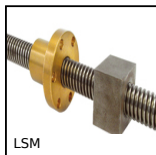

LSM

Vite trapezoidale inox  
316L, Inox - 1 filetto

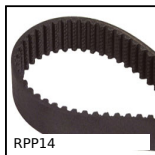

RPP14

Cinghia di  
trasmissione RPP,  
RPP14



PTKFss

Piede speciale  
agroalimentare, Dado  
cieco inox - norme 3A



PT881

Pignone di trazione,  
Serie 881



PR65C

Half-articulated foot Ø  
65, Ø 65



DB

Ingranaggio conico in  
acciaio, 2:1




PSG25

Ingranaggio dritto di  
precisione, Acciaio  
35NCD6 pretrattato




EMS

Volantino zigrinato,  
Zigrinato

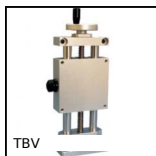

TBV

Tavola di  
posizionamento  
verticale manuale,  
12kg

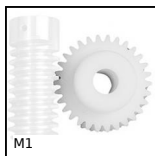

M1

Coppia ruota e vite  
senza fine, Plastica  
lavorata (delrin)



TK\_UUOP

Manicotto a sfere  
autoallineante  
Topball,  
Autoallineante Topball

## Prodotti correlati



AFSE

Perno di fissaggio, con  
chiusura a scatto



GCA

Copiglia a scatto, A  
scatto



GCT

Copiglia per tubo, Clip  
per tubo



BAB

Perno autobloccante a  
sfere, Inox temprato