

Hexagonal shaft **DIN176**

New

AHEX For manually operated bevel gearbox

- Hexagonal shaft for use with the RAM and RVM bevel gearbox ranges
- Cut to required length
- Material:
Steel




DISCOUNTS

Qty	1+	10+	25+	50+
Disc.	List	-5%	-15%	On request

Part number	Profil	Length (mm)	Price each
			1 to 9
AHEX6-1000	hex 6mm	1000	24,29 €
AHEX7-1000	hex 7mm	1000	28,93 €
AHEX9-1000	hex 9mm	1000	28,93 €

Dimensions in mm

Altri prodotti...

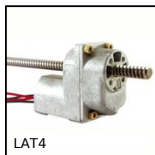

LAT4

Attuatore lineare a motore 4A, 4 ampere



PTKss

Piede speciale agroalimentare, Inox - 3-A standard



UGAC_UGET

Guida per cilindrico, Giunto per stelo filettato del martinetto



CHTRB

Riduttore a rinvio angolare a L o a T, fino a 16,5 Nm



TIF

Asta filettata - DIN975, Inox A2



LQT

Chiusura a sfera, Chiusura rapida



LC

Limitatore di coppia ad attrito, 30 a 240 Nm



BABreceptacle

Perno autobloccante, Bussola di innesto



CM

Attrezzi Hygienic Usit® and Hygienic



LVT

Mini martinetto motorizzato 4A, 4



SSE

Snodo sferico inox, Inox/PTFE



GBSz

Vite a ricircolo di sfere, Dado cilindrico

Prodotti correlati



RAM30

Riduttore manuale, Rinvio angolare



RVM14

Riduttore manuale, A ruota e vite senza fine



RVM25

Riduttore manuale, Rinvio angolare



RAM35

Riduttore manuale, Rinvio angolare