



# Protective cap

Plastic

APBBOU

- To protect adjusting rods APB-F and APB-T
- Material: flexible PVC
- Black
- Weight: 0.01 kg

## Info.


- Not sold individually, please contact us for details

## Accessories

- Adjusting rod APB-T or APB-F



With adjusting rod APB

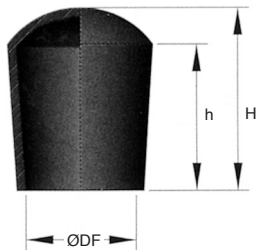

## DISCOUNTS

Qty	1+	41+	100+
Disc.	List	-5%	On request

Part number	For shaft DF	h	H	Stock*	Price each 1 to 40
APB10-BOU	10	15	18	✓	0,37 €
APB12-BOU	12	16	20	✓	0,37 €
APB14-BOU	14	17	21	✓	0,37 €
APB15-BOU	15	17	21	-	0,37 €
APB16-BOU	16	18	23	✓	0,37 €

\*Depending on availability - Dimensions in mm

## Altri prodotti...



SVG

Chiusura a leva regolabile, Corsa da 106,7mm a 121,4mm



ERT

Dado piastrina, Per scanalatura a T



M0

Coppia ruota e vite senza fine , Bronzo



SLS

Supporto per vite trapezoidale, Supporto Drylin® flottante



SSDB

Ingranaggio conico inox, 2:1



PHG05

Ingranaggio elicoidale ad assi paralleli, Acciaio 20NCD2 cementato t...



UGAC\_UGET

Guida per cilindrico, Ghiera per stelo filettato del martinetto



VTLB

Three-lobed knob, Thermoplastic / Brass or stainless steel insert



MHX

Manicotto esagonale maschiato, Esagonale - inox



AT5M AT10M

Cinghia aperta al metro tipo AT, AT5 Poliuretano armatura



NJM

Connettore rinvio d'angolo, Multiplo



SVT5

Martinetto a vite - Vite traslante, Vite traslante

## Prodotti correlati



APB\_T

Perno di fissaggio per morsetti, Maschiato



APB\_F

Perno di fissaggio per morsetti, Filettato



GMC\_GMK\_BR

Morsetto porta guide, Piatto o tondo