

- Accepts radial, axial and torque loads
- Maintenance free
- Materials:  
Cylindrical body: steel  
Insert: rubber NK50-60 Shore




**NEW!**



### Advantages

- A flexible bush is a superior replacement for a mechanical linkage where there is oscillation movement or a pivoting movement of limited amplitude

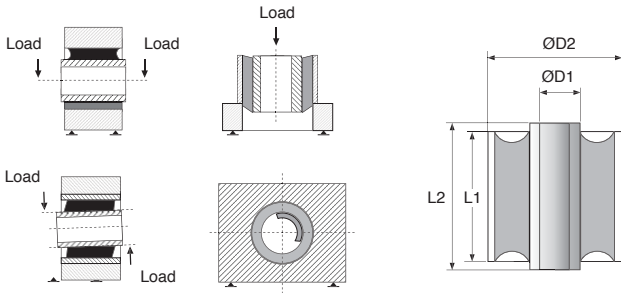

### DISCOUNTS

Qty	1+	6+	10+	15+	20+	50+
Disc.	List	-10%	-15%	-20%	-25%	On request

Part number	ØD1	ØD2	L1	L2	Price each 1 to 5
ARTE8-16-17	8	16	15	17	9,16 €
ARTE8-16-28	8	16	25	28	10,72 €
ARTE8-20-17	8	20	15	17	9,42 €
ARTE8-22-16	8	22	10	16	10,52 €
ARTE10-18-20	10	18	18	20	11,46 €
ARTE10-20-24	10	20	20	24	21,79 €
ARTE10-22-17	10	22	15	17	9,51 €
ARTE10-22-30	10	22	25	30	10,23 €
ARTE10-24-17	10	24	14	17	11,95 €
ARTE10-25-24	10	25	20	24	12,18 €
ARTE10-27-51	10	27	45	51	12,18 €

Dimensions in mm

NEW!

## DISCOUNTS

Qty	1+	6+	10+	15+	20+	50+
Disc.	List	-10%	-15%	-20%	-25%	On request

Part number	ØD1	ØD2	L1	L2	Price each 1 to 5
ARTE12-22-24	12	22	22	24	10,72 €
ARTE12-24-38	12	24	35	38	13,15 €
ARTE12-25-28	12	25	25	28	12,43 €
ARTE12-26-24	12	26	20	24	10,23 €
ARTE12-26-36	12	26	32	36	12,67 €
ARTE12-27-51	12	27	45	51	17,54 €
ARTE12-27-68	12	27	60	68	19,00 €
ARTE12-30-28	12	30	25	28	15,59 €
ARTE12-30-34	12	30	28	34	15,59 €
ARTE12-30-40	12	30	36	40	18,41 €
ARTE12-30-44	12	30	39	44	18,51 €
ARTE12-36-38	12	36	30	38	21,44 €
ARTE13-30-40	13	30	40	40	18,51 €
ARTE14-30-28	14	30	25	28	17,54 €
ARTE14-30-76	14	30	67	76	19,25 €
ARTE14-34-40	14	34	32	40	21,92 €
ARTE14-46-45	14	46	37	45	30,95 €
ARTE16-32-28	16	32	25	28	23,87 €
ARTE16-32-54	16	32	50	54	23,87 €
ARTE16-35-62	16	35	58	62	26,11 €
ARTE16-40-38	16	40	32	38	23,87 €
ARTE18-34-36	18	34	32	36	20,46 €
ARTE18-34-42	18	34	36	42	20,46 €
ARTE20-44-42	20	44	38	42	25,10 €
ARTE20-45-30	20	45	30	30	21,92 €
ARTE20-45-62	20	45	55	62	33,62 €
ARTE20-45-70	20	45	64	70	36,54 €
ARTE25-40-40	25	40	40	40	30,21 €
ARTE25-45-56	25	45	50	56	33,62 €
ARTE30-60-68	30	60	60	68	36,54 €
ARTE30-65-70	30	65	70	70	42,39 €
ARTE32-56-55	32	56	50	55	47,26 €
ARTE40-75-70	40	75	57	70	74,83 €
ARTE45-75-100	45	75	90	100	94,52 €
ARTE50-70-60	50	70	60	60	70,16 €
ARTE50-80-100	50	80	95	100	97,44 €

Dimensions in mm

## Altri prodotti...



ZBconique

Ingranaggio conico in  
plastica, 1:1



FF50

Riduttore ad alberi  
paralleli, da 111 a 425  
Nm



PTKFss

Piede speciale  
agroalimentare, Dado  
cieco inox - norme 3A



PW\_PWG15

Vite senza fine di  
precisione, Acciaio



METEB

Barre autolubrificanti,  
Bronzo BP25



BPVM

Sfera portante  
avvitabile miniatura,  
Miniatura ad avvitare



BLHM60

Rinvio angolare, fino a  
70 Nm



CDP

Boccola di  
posizionamento,  
Acciaio



HTD8M\_30

Puleggia dentata di  
trasmissione tipo



DFG

Ventosa, nitrile



CLSCLP

Forcella serie corta,  
Corta acciaio



FIRSTDC1Q60

Variatore di velocità  
10A, 10 A

**Prodotti correlati**