

AT type tooth bar stock



AT5-BAR

Aluminium




- Bar stock to be cut to length by the customer
- The overall length is the same as the maximum length
- Material : Aluminium suitable for hard anodic oxidation
- Finish : Supplied not-treated



Info.

- We are unable to modify this product

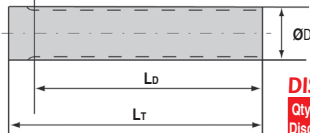

-30%**

DISCOUNTS

Qty.	1+	6+	20+	40+	60+	100+
Disc.	List -12%	-25%	-33%	-37%	On request	

Part number	Z Teeth	ØD External	Length of teeth L _b	Total length L _r	Price each 1 to 5
12AT5-BAR	12	17,85	140	140	17,67 €
13AT5-BAR	13	19,45	140	140	17,95 €
14AT5-BAR	14	21,05	140	140	19,96 €
15AT5-BAR	15	22,65	140	140	21,07 €
16AT5-BAR	16	24,20	140	140	22,44 €
18AT5-BAR	18	27,40	140	140	26,63 €
19AT5-BAR	19	29,00	140	140	28,49 €
20AT5-BAR	20	30,60	160	160	30,77 €
21AT5-BAR	21	32,30	160	160	31,99 €
22AT5-BAR	22	33,85	160	160	34,54 €
23AT5-BAR	23	35,45	160	160	35,34 €
24AT5-BAR	24	37,00	160	160	37,06 €
25AT5-BAR	25	38,55	160	160	41,16 €
26AT5-BAR	26	40,20	160	160	44,44 €
28AT5-BAR	28	43,25	160	160	46,87 €
30AT5-BAR	30	46,55	160	160	52,39 €
32AT5-BAR	32	49,70	160	160	57,64 €
34AT5-BAR	34	52,85	160	160	64,84 €
36AT5-BAR	36	56,05	160	160	67,96 €
38AT5-BAR	38	59,25	160	160	75,68 €
40AT5-BAR	40	62,45	160	160	79,86 €
42AT5-BAR	42	65,60	160	160	88,38 €
44AT5-BAR	44	68,80	160	160	97,07 €
46AT5-BAR	46	72,00	160	160	99,66 €
48AT5-BAR	48	75,15	160	160	107,39 €
52AT5-BAR	52	81,55	160	160	114,88 €
56AT5-BAR	56	87,90	160	160	114,88 €
60AT5-BAR	60	94,25	160	160	161,20 €
64AT5-BAR	64	100,65	160	160	161,20 €
72AT5-BAR	72	113,35	160	160	226,24 €

Dimensions in mm

Altri prodotti...



PW_PWG1
Ruota di precisione,
Bronzo



E15
Riduttore a rinvio
angolare, da 0.40 a
2.53 Nm



MCL
Manicotto cilindrico
maschiato, Cilindrico -
inox



LVT
Mini martinetto
motorizzato 1A, 1
ampere



PAS
Maniglia a ponte,
Reinforced PA
thermoplastic



DOG258
Motoriduttore DC 12V
e 24V DC, da 12 a 15
Nm



R204
Molla per stampe
ISO10243, Medio



gt64
Chiusura a farfalla,
Tolleranze di
montaggio normali



AC
Piastrina di riscontro,
15mm



PRF-CHAR-POU
Attrezzi, Carrello
attrezzi



PPG
Pistoncino a molla,
Con flangia di
fissaggio orizzontale



Gdal
Giunto cardanico
doppio serie eco,
Sollecitazioni leggere

Prodotti correlati



AT10-BAR
Barra dentata, AT10



AT5-10ECO
Puleggia dentata di
posizionamento tipo
AT, Serie economica -
AT5 al...



AT5-16ECO
Puleggia dentata di
posizionamento tipo
AT, Serie economica -
AT5 al...



AT5-25ECO
Puleggia dentata di
posizionamento tipo
AT, Serie economica -
AT5 al...