

# AT type tooth bar stock



## AT5-BAR

## Aluminium




- Bar stock to be cut to length by the customer
- The overall length is the same as the maximum length
- Material : Aluminium suitable for hard anodic oxidation
- Finish : Supplied not-treated



### Info.

- We are unable to modify this product

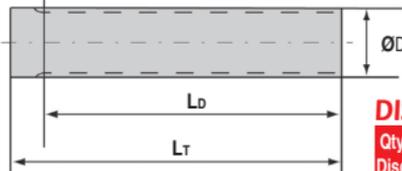

**-30%\*\***

### DISCOUNTS

Qty.	1+	6+	20+	40+	60+	100+
Disc.	List -12%	-25%	-33%	-37%	On request	

Part number	Z Teeth	ØD External	Length of teeth L <sub>b</sub>	Total length L <sub>r</sub>	Price each 1 to 5
12AT5-BAR	12	17,85	140	140	17,67 €
13AT5-BAR	13	19,45	140	140	17,95 €
14AT5-BAR	14	21,05	140	140	19,96 €
15AT5-BAR	15	22,65	140	140	21,07 €
16AT5-BAR	16	24,20	140	140	22,44 €
18AT5-BAR	18	27,40	140	140	26,63 €
19AT5-BAR	19	29,00	140	140	28,49 €
20AT5-BAR	20	30,60	160	160	30,77 €
21AT5-BAR	21	32,30	160	160	31,99 €
22AT5-BAR	22	33,85	160	160	34,54 €
23AT5-BAR	23	35,45	160	160	35,34 €
24AT5-BAR	24	37,00	160	160	37,06 €
25AT5-BAR	25	38,55	160	160	41,16 €
26AT5-BAR	26	40,20	160	160	44,44 €
28AT5-BAR	28	43,25	160	160	46,87 €
30AT5-BAR	30	46,55	160	160	52,39 €
32AT5-BAR	32	49,70	160	160	57,64 €
34AT5-BAR	34	52,85	160	160	64,84 €
36AT5-BAR	36	56,05	160	160	67,96 €
38AT5-BAR	38	59,25	160	160	75,68 €
40AT5-BAR	40	62,45	160	160	79,86 €
42AT5-BAR	42	65,60	160	160	88,38 €
44AT5-BAR	44	68,80	160	160	97,07 €
46AT5-BAR	46	72,00	160	160	99,66 €
48AT5-BAR	48	75,15	160	160	107,39 €
52AT5-BAR	52	81,55	160	160	114,88 €
56AT5-BAR	56	87,90	160	160	114,88 €
60AT5-BAR	60	94,25	160	160	161,20 €
64AT5-BAR	64	100,65	160	160	161,20 €
72AT5-BAR	72	113,35	160	160	226,24 €

Dimensions in mm

## Altri prodotti...



APB\_T  
Perno di fissaggio per morsetti, Maschiato



SLHHlok  
Bloccaggio a leva, A leva orizzontale / base orizzontale



ACLCHARJ  
Cerniera ad avvitare, Adjusts in 2 directions



PCAtherm  
Pull handle, Thermoplastic



S2B  
Supporto corto per manicotto chiuso a sfere, Chiuso - Corto



VP  
Volantino a 6 lobi, Duroplast - Acciaio



BS2  
Panamech, Multi-Beam, Alluminio - con vite a pressione



PTA80ssEB  
Piede snodato con base stampata Ø80, 10000N



CM\_CO  
Attrezzi Hygienic Usit® and Hygienic



CMA  
Vite ad occhio, Acciaio



SVT15  
Martinetto a vite - Vite traslante, Vite



NTM  
Grano punta in nylon, punta in nylon

## Prodotti correlati



AT10-BAR  
Barra dentata, AT10



AT5-10ECO  
Puleggia dentata di posizionamento tipo AT, Serie economica - AT5 al...



AT5-16ECO  
Puleggia dentata di posizionamento tipo AT, Serie economica - AT5 al...



AT5-25ECO  
Puleggia dentata di posizionamento tipo AT, Serie economica - AT5 al...