

Mounting collar for clamping pin

Sta

BABFC
BABFO

With a round or oval flange



- For use on thin sheet metal
- These collars offer a quick and securing method of mounting ball pins
- For the construction of boxes or other containers
- Material: 303, stainless steel




stainless steel

Operation principle


- The large contact surface area ensures that all the force is spread evenly over thin walled structures

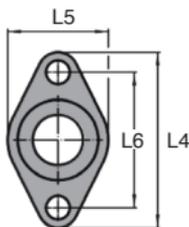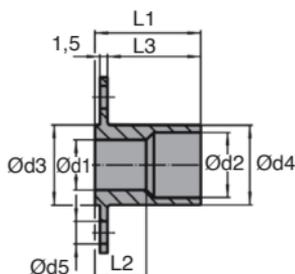

BABFO :
Oval flange

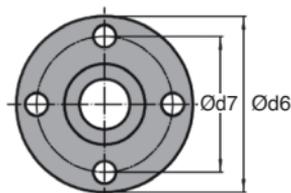

BABFC :
Cylindrical flange

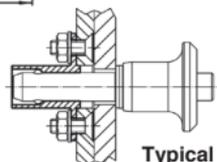

Typical application

DISCOUNTS

Qty	1+	6+	10+	25+
Disc.	List	-5%	-10%	On request

with cylindrical flange

Part number	Ød1	Ød2	Ød3		Ød4	Ød5	Ød6	Ød7	L1	L2	L3	Weight (g)	Price each 1 to 5
			-0,05	-0,1									
BAB5-8/FC/SS	5	8	10	9,9	3,4	25	19	12	5,4	9,5	9	23,70 €	
BAB6-8/FC/SS	6	8	10	9,9	3,4	25	19	13	5,3	10,5	9	23,70 €	
BAB8-10/FC/SS	8	10	12	11,9	4,5	30	22	19	10,3	16,5	14	26,37 €	
BAB10-13/FC/SS	10	13	16	15,9	4,5	35	27	21	10,2	18,5	24	29,15 €	
BAB12-15/FC/SS	12	15	19	18,9	4,5	40	30	27	15,2	24,5	41	33,17 €	
BAB16-20/FC/SS	16	20	24	23,9	5,5	50	40	30	15,3	27,5	63	38,98 €	

with oval flange

Part number	Ød1	Ød2	Ød3		Ød4	Ød5	L1	L2	L3	L4	L5	L6	Weight (g)	Price each 1 to 5
			-0,05	-0,1										
BAB5-8/FO/SS	5	8	10	9,9	3,4	12	5,4	9,5	25	15	19	6	27,36 €	
BAB6-8/FO/SS	6	8	10	9,9	3,4	13	5,3	10,5	25	15	19	6	27,36 €	
BAB8-10/FO/SS	8	10	12	11,9	4,5	19	10,3	16,5	30	18	22	10	30,66 €	
BAB10-13/FO/SS	10	13	16	15,9	4,5	21	10,2	18,5	35	20	27	19	33,91 €	
BAB12-15/FO/SS	12	15	19	18,9	4,5	27	15,2	24,5	40	24	30	34	37,92 €	
BAB16-20/FO/SS	16	20	24	23,9	5,5	30	15,3	27,5	50	30	40	52	41,97 €	

Dimensions in mm


- Allows ball pins to be positioned quickly and more securely
- Material:
Stainless steel 1.4305 (303)

Advantages


- Precision collar means optimised centring
- Simple and safe assembly
- Suitable for use with different materials
- Suitable for use with thin walled materials
- Corrosion resistant
- Wear resistant
- Can be mounted from either side

Simple and safe assembly


stainless steel

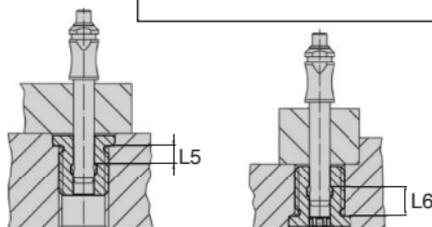

Hexagonal head

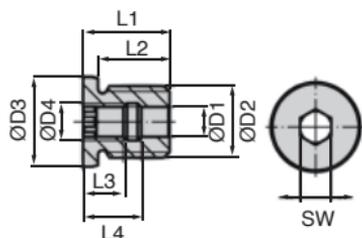

Hexagonal socket

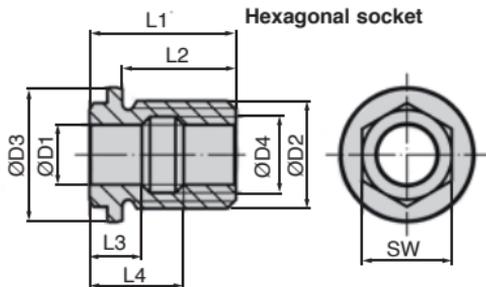

DISCOUNTS

Qty	1+	6+	10+
Disc.	List	-5%	On request

Part number	ØD1		ØD2	ØD3	ØD4	L1	L2	L3	L4	L5	L6	SW	Weight (g)	Price each 1 to 5
	H11													
Hexagonal head														
BAB5-M12	5	M12	18	6,0	19	15	9,0	13,0	5,1	9,0	5	15	23,43	€
BAB6-M12	6	M12	18	7,5	19	15	9,4	13,0	5,6	8,8	6	13	23,43	€
BAB8-M16	8	M16	22	10,0	25	20	12,0	17,0	7,3	11,7	8	29	34,59	€
BAB10-M24	10	M24	30	12,5	29	24	13,5	19,5	8,9	14,1	10	75	40,16	€
BAB12-M24	12	M24	30	15,0	29	24	14,0	20,0	9,6	14,4	12	66	41,50	€
Hexagonal socket														
BAB16-M30	16	M30	36	19,5	39	29	15,5	23,5	6,1	12,8	24	124	45,69	€
BAB20-M36	20	M36	45	25,5	49	38	17,5	31,5	7,7	19,3	30	208	76,15	€

Dimensions in mm