

Ball lock pins lockable



BABv

With simple grip

- Lockable version prevents **unintentional loosening of the connection**
- The balls can only be unlocked using a key
- Materials :
 - Handle: red thermoplastic (RAL3020)
 - Shaft: 303 stainless steel
 - Components: stainless steel
 - Lock: Die cast zinc
 - Key: Zinc-plated steel
- For H11 bore


Advantages

- Press to unlock
- Quick and easy to assemble, block, adjust, change and stop
- Simply and quickly released when performing repetitive operations
- Corrosion resistant
- Resists high loads
- Ergonomic handle
- Can be fitted with **CDR** retaining cable (**tome 1 p.35**)

Infos

- Shear strength to DIN 50141
- The push-button lock has identical locking. All cylinders can be opened with the same key. Lockable locking pins are supplied with two keys



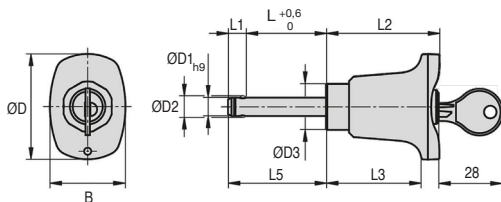

DISCOUNTS

Qty	1+	6+	10+
Disc. List	-5%	-5%	On request

Part Number	B	ØD	ØD1	ØD2	ØD3	L	L1	L2	L3	L5	Double shear resistance kN min	Price each 1 to 5
BAB8-20/V/R	33	45,9	8	9,5	20	20	7,8	49,5	41,3	27,8	38	43,94 €
BAB8-25/V/R	33	45,9	8	9,5	20	25	7,8	49,5	41,3	32,8	38	43,94 €
BAB8-30/V/R	33	45,9	8	9,5	20	30	7,8	49,5	41,3	37,8	38	47,10 €
BAB8-35/V/R	33	45,9	8	9,5	20	35	7,8	49,5	41,3	42,8	38	47,10 €
BAB8-40/V/R	33	45,9	8	9,5	20	40	7,8	49,5	41,3	47,8	38	47,10 €
BAB8-45/V/R	33	45,9	8	9,5	20	45	7,8	49,5	41,3	52,8	38	47,10 €
BAB8-50/V/R	33	45,9	8	9,5	20	50	7,8	49,5	41,3	57,8	38	47,10 €
BAB10-20/V/R	33	45,9	10	12,0	20	20	8,9	49,5	41,3	28,9	60	61,41 €
BAB10-25/V/R	33	45,9	10	12,0	20	25	8,9	49,5	41,3	33,9	60	61,41 €
BAB10-30/V/R	33	45,9	10	12,0	20	30	8,9	49,5	41,3	38,9	60	64,08 €
BAB10-35/V/R	33	45,9	10	12,0	20	35	8,9	49,5	41,3	43,9	60	64,08 €
BAB10-40/V/R	33	45,9	10	12,0	20	40	8,9	49,5	41,3	48,9	60	64,08 €
BAB10-45/V/R	33	45,9	10	12,0	20	45	8,9	49,5	41,3	53,9	60	64,08 €
BAB10-50/V/R	33	45,9	10	12,0	20	50	8,9	49,5	41,3	58,9	60	64,08 €
BAB10-60/V/R	33	45,9	10	12,0	20	60	8,9	49,5	41,3	68,9	60	67,40 €
BAB12-25/V/R	33	45,9	12	14,5	20	25	9,9	49,5	41,3	34,9	86	55,18 €
BAB12-30/V/R	33	45,9	12	14,5	20	30	9,9	49,5	41,3	39,9	86	58,16 €
BAB12-35/V/R	33	45,9	12	14,5	20	35	9,9	49,5	41,3	44,9	86	58,16 €
BAB12-40/V/R	33	45,9	12	14,5	20	40	9,9	49,5	41,3	49,9	86	58,16 €
BAB12-45/V/R	33	45,9	12	14,5	20	45	9,9	49,5	41,3	54,9	86	58,16 €
BAB12-50/V/R	33	45,9	12	14,5	20	50	9,9	49,5	41,3	59,9	86	58,16 €
BAB12-60/V/R	33	45,9	12	14,5	20	60	9,9	49,5	41,3	69,9	86	61,14 €
BAB12-70/V/R	33	45,9	12	14,5	20	70	9,9	49,5	41,3	79,9	86	61,14 €
BAB12-80/V/R	33	45,9	12	14,5	20	80	9,9	49,5	41,3	89,9	86	63,78 €
BAB16-30/V/R	33	45,9	16	19	20	30	13,1	49,5	41,3	43,1	153	81,76 €
BAB16-35/V/R	33	45,9	16	19	20	35	13,1	49,5	41,3	48,1	153	83,07 €
BAB16-40/V/R	33	45,9	16	19	20	40	13,1	49,5	41,3	53,1	153	83,07 €
BAB16-45/V/R	33	45,9	16	19	20	45	13,1	49,5	41,3	58,1	153	83,07 €
BAB16-50/V/R	33	45,9	16	19	20	50	13,1	49,5	41,3	63,1	153	83,07 €
BAB16-60/V/R	33	45,9	16	19	20	60	13,1	49,5	41,3	73,1	153	88,27 €
BAB16-70/V/R	33	45,9	16	19	20	70	13,1	49,5	41,3	83,1	153	88,27 €
BAB16-80/V/R	33	45,9	16	19	20	80	13,1	49,5	41,3	93,1	153	93,43 €

Dimensions in mm

Altri prodotti...



Q6
Cuscinetto radiale a sfere, Acciaio



CHAR7530
Cerniera a molla, saldabile



LVT
Mini martinetto motorizzato 2A, 2 ampere



TFR
Tenditore rigido, Fisso



MFBC
Giunto a soffietto, Alluminio e bronzo - con ganaschia di serraggio



OPFL_OPPM
Accessorio per indicatori, Pomello di manovra



PAM_SS
Piede snodato con base lamiera, Ø 30 & 40



PRF_GAL
Rotella per profilo alluminio, Rotella cava Ø12



CHA_GC_9SS
Cerniera a bandiera inox, A saldare



GE1006
Chiusura a leva adattabile, Per



ACLBMC
Supporto per sensore per profili alluminio,



PITA
Pistoncino a molla, con maniglia a T

Prodotti correlati



BABTV
Ball lock pins lockable, Stainless steel



BABreceptacle
Perno autobloccante, Bussola di innesto



BABFCFO
Perno autobloccante, Boccole di fissaggio con flangia cilindrica



BABFCFO
Perno autobloccante, Boccole di fissaggio con flangia ovale