

Ball lock pins lockable



BABv

With simple grip

- Lockable version prevents unintentional loosening of the connection
- The balls can only be unlocked using a key
- Materials :
 - Handle: red thermoplastic (RAL3020)
 - Shaft: 303 stainless steel
 - Components: stainless steel
 - Lock: Die cast zinc
 - Key: Zinc-plated steel
- For H11 bore


Advantages

- Press to unlock
- Quick and easy to assemble, block, adjust, change and stop
- Simply and quickly released when performing repetitive operations
- Corrosion resistant
- Resists high loads
- Ergonomic handle
- Can be fitted with CDR retaining cable (tome **i** p.35)

Infos

- Shear strength to DIN 50141
- The push-button lock has identical locking. All cylinders can be opened with the same key. Lockable locking pins are supplied with two keys



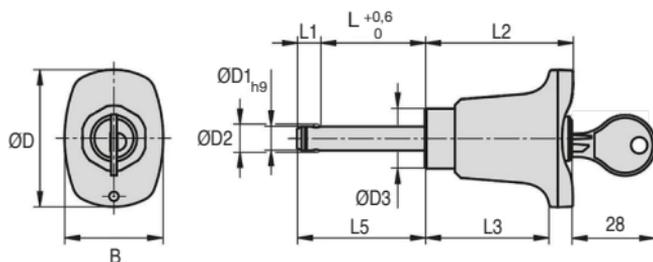

DISCOUNTS

Qty	1+	6+	10+
Disc. List	-5%	-5%	On request

Part Number	B	ØD	ØD1	ØD2	ØD3	L	L1	L2	L3	L5	Double shear resistance kN min	Price each 1 to 5
BAB8-20/V/R	33	45,9	8	9,5	20	20	7,8	49,5	41,3	27,8	38	43,94 €
BAB8-25/V/R	33	45,9	8	9,5	20	25	7,8	49,5	41,3	32,8	38	43,94 €
BAB8-30/V/R	33	45,9	8	9,5	20	30	7,8	49,5	41,3	37,8	38	47,10 €
BAB8-35/V/R	33	45,9	8	9,5	20	35	7,8	49,5	41,3	42,8	38	47,10 €
BAB8-40/V/R	33	45,9	8	9,5	20	40	7,8	49,5	41,3	47,8	38	47,10 €
BAB8-45/V/R	33	45,9	8	9,5	20	45	7,8	49,5	41,3	52,8	38	47,10 €
BAB8-50/V/R	33	45,9	8	9,5	20	50	7,8	49,5	41,3	57,8	38	47,10 €
BAB10-20/V/R	33	45,9	10	12,0	20	20	8,9	49,5	41,3	28,9	60	61,41 €
BAB10-25/V/R	33	45,9	10	12,0	20	25	8,9	49,5	41,3	33,9	60	61,41 €
BAB10-30/V/R	33	45,9	10	12,0	20	30	8,9	49,5	41,3	38,9	60	64,08 €
BAB10-35/V/R	33	45,9	10	12,0	20	35	8,9	49,5	41,3	43,9	60	64,08 €
BAB10-40/V/R	33	45,9	10	12,0	20	40	8,9	49,5	41,3	48,9	60	64,08 €
BAB10-45/V/R	33	45,9	10	12,0	20	45	8,9	49,5	41,3	53,9	60	64,08 €
BAB10-50/V/R	33	45,9	10	12,0	20	50	8,9	49,5	41,3	58,9	60	64,08 €
BAB10-60/V/R	33	45,9	10	12,0	20	60	8,9	49,5	41,3	68,9	60	67,40 €
BAB12-25/V/R	33	45,9	12	14,5	20	25	9,9	49,5	41,3	34,9	86	55,18 €
BAB12-30/V/R	33	45,9	12	14,5	20	30	9,9	49,5	41,3	39,9	86	58,16 €
BAB12-35/V/R	33	45,9	12	14,5	20	35	9,9	49,5	41,3	44,9	86	58,16 €
BAB12-40/V/R	33	45,9	12	14,5	20	40	9,9	49,5	41,3	49,9	86	58,16 €
BAB12-45/V/R	33	45,9	12	14,5	20	45	9,9	49,5	41,3	54,9	86	58,16 €
BAB12-50/V/R	33	45,9	12	14,5	20	50	9,9	49,5	41,3	59,9	86	58,16 €
BAB12-60/V/R	33	45,9	12	14,5	20	60	9,9	49,5	41,3	69,9	86	61,14 €
BAB12-70/V/R	33	45,9	12	14,5	20	70	9,9	49,5	41,3	79,9	86	61,14 €
BAB12-80/V/R	33	45,9	12	14,5	20	80	9,9	49,5	41,3	89,9	86	63,78 €
BAB16-30/V/R	33	45,9	16	19	20	30	13,1	49,5	41,3	43,1	153	81,76 €
BAB16-35/V/R	33	45,9	16	19	20	35	13,1	49,5	41,3	48,1	153	83,07 €
BAB16-40/V/R	33	45,9	16	19	20	40	13,1	49,5	41,3	53,1	153	83,07 €
BAB16-45/V/R	33	45,9	16	19	20	45	13,1	49,5	41,3	58,1	153	83,07 €
BAB16-50/V/R	33	45,9	16	19	20	50	13,1	49,5	41,3	63,1	153	83,07 €
BAB16-60/V/R	33	45,9	16	19	20	60	13,1	49,5	41,3	73,1	153	88,27 €
BAB16-70/V/R	33	45,9	16	19	20	70	13,1	49,5	41,3	83,1	153	88,27 €
BAB16-80/V/R	33	45,9	16	19	20	80	13,1	49,5	41,3	93,1	153	93,43 €

Dimensions in mm

Altri prodotti...



PLM-205C

Magnete cilindrico di fermo filettato, Magnete di fermo maschiato



GLB

Volantino a 6 lobi filettato, Tecnopolimero - Inox



RBGpl

Ruota fissa con piastra, Acciaio - gomma grigia



SHS

Vite a spalla inox 303, Inox 303



ZG125

Ingranaggio dritto in plastica, Plastica lavorata (delrin)



PW_PWG15

Vite senza fine di precisione, Inox



PGMT

Maniglia a ponte a fissaggio anteriore, Inox



TPEpbd

Ruota per profili alluminio, Girevole con freno



LVT

Mini martinetto motorizzato 4A, 4



SBRtool

Chain tool, Drive chain maintenance



BCM_CC

Spazzola cilindrica modulare, Filo di crine



M

Manicotto per giunto cardanico, Accessori

Prodotti correlati



BABTV

Ball lock pins lockable, Stainless steel



BABreceptacle

Perno autobloccante, Bussola di innesto



BABFCFO

Perno autobloccante, Boccole di fissaggio con flangia cilindrica



BABFCFO

Perno autobloccante, Boccole di fissaggio con flangia ovale