

Ball lock pins lockable



BABv

With simple grip

- Lockable version prevents **unintentional loosening of the connection**
- The balls can only be unlocked using a key
- Materials :
 - Handle: red thermoplastic (RAL3020)
 - Shaft: 303 stainless steel
 - Components: stainless steel
 - Lock: Die cast zinc
 - Key: Zinc-plated steel
- For H11 bore


Advantages

- Press to unlock
- Quick and easy to assemble, block, adjust, change and stop
- Simply and quickly released when performing repetitive operations
- Corrosion resistant
- Resists high loads
- Ergonomic handle
- Can be fitted with **CDR retaining cable (tome 1 p.35)**

Infos

- Shear strength to DIN 50141
- The push-button lock has identical locking. All cylinders can be opened with the same key. Lockable locking pins are supplied with two keys



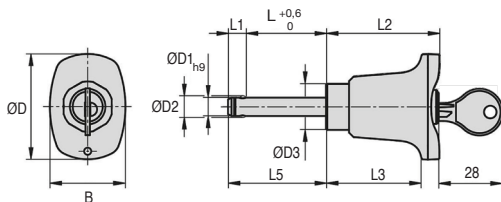

DISCOUNTS

Qty	1+	6+	10+
Disc. List	-5%	-5%	On request

Part Number	B	ØD	ØD1	ØD2	ØD3	L	L1	L2	L3	L5	Double shear resistance kN min	Price each 1 to 5
BAB8-20/V/R	33	45,9	8	9,5	20	20	7,8	49,5	41,3	27,8	38	43,94 €
BAB8-25/V/R	33	45,9	8	9,5	20	25	7,8	49,5	41,3	32,8	38	43,94 €
BAB8-30/V/R	33	45,9	8	9,5	20	30	7,8	49,5	41,3	37,8	38	47,10 €
BAB8-35/V/R	33	45,9	8	9,5	20	35	7,8	49,5	41,3	42,8	38	47,10 €
BAB8-40/V/R	33	45,9	8	9,5	20	40	7,8	49,5	41,3	47,8	38	47,10 €
BAB8-45/V/R	33	45,9	8	9,5	20	45	7,8	49,5	41,3	52,8	38	47,10 €
BAB8-50/V/R	33	45,9	8	9,5	20	50	7,8	49,5	41,3	57,8	38	47,10 €
BAB10-20/V/R	33	45,9	10	12,0	20	20	8,9	49,5	41,3	28,9	60	61,41 €
BAB10-25/V/R	33	45,9	10	12,0	20	25	8,9	49,5	41,3	33,9	60	61,41 €
BAB10-30/V/R	33	45,9	10	12,0	20	30	8,9	49,5	41,3	38,9	60	64,08 €
BAB10-35/V/R	33	45,9	10	12,0	20	35	8,9	49,5	41,3	43,9	60	64,08 €
BAB10-40/V/R	33	45,9	10	12,0	20	40	8,9	49,5	41,3	48,9	60	64,08 €
BAB10-45/V/R	33	45,9	10	12,0	20	45	8,9	49,5	41,3	53,9	60	64,08 €
BAB10-50/V/R	33	45,9	10	12,0	20	50	8,9	49,5	41,3	58,9	60	64,08 €
BAB10-60/V/R	33	45,9	10	12,0	20	60	8,9	49,5	41,3	68,9	60	67,40 €
BAB12-25/V/R	33	45,9	12	14,5	20	25	9,9	49,5	41,3	34,9	86	55,18 €
BAB12-30/V/R	33	45,9	12	14,5	20	30	9,9	49,5	41,3	39,9	86	58,16 €
BAB12-35/V/R	33	45,9	12	14,5	20	35	9,9	49,5	41,3	44,9	86	58,16 €
BAB12-40/V/R	33	45,9	12	14,5	20	40	9,9	49,5	41,3	49,9	86	58,16 €
BAB12-45/V/R	33	45,9	12	14,5	20	45	9,9	49,5	41,3	54,9	86	58,16 €
BAB12-50/V/R	33	45,9	12	14,5	20	50	9,9	49,5	41,3	59,9	86	58,16 €
BAB12-60/V/R	33	45,9	12	14,5	20	60	9,9	49,5	41,3	69,9	86	61,14 €
BAB12-70/V/R	33	45,9	12	14,5	20	70	9,9	49,5	41,3	79,9	86	61,14 €
BAB12-80/V/R	33	45,9	12	14,5	20	80	9,9	49,5	41,3	89,9	86	63,78 €
BAB16-30/V/R	33	45,9	16	19	20	30	13,1	49,5	41,3	43,1	153	81,76 €
BAB16-35/V/R	33	45,9	16	19	20	35	13,1	49,5	41,3	48,1	153	83,07 €
BAB16-40/V/R	33	45,9	16	19	20	40	13,1	49,5	41,3	53,1	153	83,07 €
BAB16-45/V/R	33	45,9	16	19	20	45	13,1	49,5	41,3	58,1	153	83,07 €
BAB16-50/V/R	33	45,9	16	19	20	50	13,1	49,5	41,3	63,1	153	83,07 €
BAB16-60/V/R	33	45,9	16	19	20	60	13,1	49,5	41,3	73,1	153	88,27 €
BAB16-70/V/R	33	45,9	16	19	20	70	13,1	49,5	41,3	83,1	153	88,27 €
BAB16-80/V/R	33	45,9	16	19	20	80	13,1	49,5	41,3	93,1	153	93,43 €

Dimensions in mm

Altri prodotti...



PRF4545_P
 Profilato alluminio per camera bianca, 45 x 45 mm




GE_ES
 Snodo sferico, acciaio/acciaio



MFB_MHB
 Ingranaggio conico in plastica stampata, 4:1



NCT
 Giunto di collegamento, Ad angolo fisso

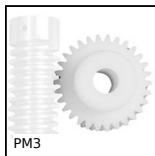


PM3
 Ruota per vite senza fine, Plastica lavorata (delrin)



GCT
 Copiglia per tubo, Clip per tubo



RJA10_03
 Guarnizione in gomma, Da agganciare

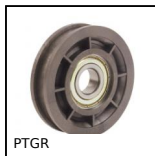

PTGR
 Puleggia folle, Per cinghia tonda



EHD08-3
 Riduttore coassiale, da 20 a 50 Nm



FCHN_CHNSS
 Catena dritta a maglie lunghe, Acciaio zincato



MFBSC
 Giunto a soffietto Inox, Inox - con ganascia di serraggio



DOMI30
 Accessori di collegamento, Piatto girevole

Prodotti correlati



BABTV
 Ball lock pins lockable, Stainless steel



BABreceptacle
 Perno autobloccante, Bussola di innesto



BABFCFO
 Perno autobloccante, Boccole di fissaggio con flangia cilindrica



BABFCFO
 Perno autobloccante, Boccole di fissaggio con flangia ovale