

- Self locking

- Materials:

Body: Stainless steel 303, natural finish

Spring: Stainless steel 301

Pin: Stainless steel

- Max working temp: 250°C





Advantages

- Handle shape protects button to prevent any inadvertent operation
- Press to unlock
- Quick to insert, block, change and stop
- Simply and easily released when performing repetitive operations
- Corrosion resistant

Accessory

- CDR retaining cable

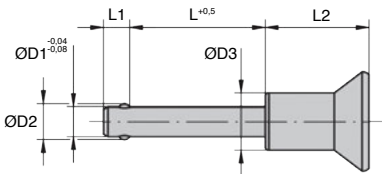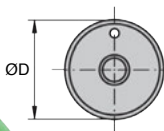

DISCOUNTS

Qty	1+	6+	10+	25+
Disc.	List	-5%	-10%	On request

Part number	ØD	ØD1	ØD2	ØD3	L	L1	L2	For bore H11	Double shear strength (kN)	Price each 1 to 5
BAB5-10/P/SS	25	5	5,5	14	10	6	26,5	5	15	16,38 €
BAB5-15/P/SS	25	5	5,5	14	15	6	26,5	5	15	16,69 €
BAB5-20/P/SS	25	5	5,5	14	20	6	26,5	5	15	16,98 €
BAB5-25/P/SS	25	5	5,5	14	25	6	26,5	5	15	18,24 €
BAB5-30/P/SS	25	5	5,5	14	30	6	26,5	5	15	18,52 €
BAB6-10/P/SS	25	6	6,85	14	10	7	26,5	6	22	17,46 €
BAB6-15/P/SS	25	6	6,85	14	15	7	26,5	6	22	18,04 €
BAB6-20/P/SS	25	6	6,85	14	20	7	26,5	6	22	18,47 €
BAB6-25/P/SS	25	6	6,85	14	25	7	26,5	6	22	18,87 €
BAB6-30/P/SS	25	6	6,85	14	30	7	26,5	6	22	19,55 €
BAB6-35/P/SS	25	6	6,85	14	35	7	26,5	6	22	20,02 €
BAB6-40/P/SS	25	6	6,85	14	40	7	26,5	6	22	20,46 €
BAB6-45/P/SS	25	6	6,85	14	45	7	26,5	6	22	21,36 €
BAB6-50/P/SS	25	6	6,85	14	50	7	26,5	6	22	21,84 €
BAB8-20/P/SS	25	8	9,5	14	20	8	26,5	8	38	18,64 €
BAB8-25/P/SS	25	8	9,5	14	25	8	26,5	8	38	19,02 €
BAB8-30/P/SS	25	8	9,5	14	30	8	26,5	8	38	19,39 €
BAB8-35/P/SS	25	8	9,5	14	35	8	26,5	8	38	19,80 €
BAB8-40/P/SS	25	8	9,5	14	40	8	26,5	8	38	20,18 €
BAB8-45/P/SS	25	8	9,5	14	45	8	26,5	8	38	20,58 €
BAB8-50/P/SS	25	8	9,5	14	50	8	26,5	8	38	20,95 €
BAB10-20/P/SS	33	10	12	19	20	9	34,6	10	60	19,88 €
BAB10-25/P/SS	33	10	12	19	25	9	34,6	10	60	20,15 €
BAB10-30/P/SS	33	10	12	19	30	9	34,6	10	60	20,55 €
BAB10-35/P/SS	33	10	12	19	35	9	34,6	10	60	20,91 €
BAB10-40/P/SS	33	10	12	19	40	9	34,6	10	60	21,26 €
BAB10-45/P/SS	33	10	12	19	45	9	34,6	10	60	21,58 €
BAB10-50/P/SS	33	10	12	19	50	9	34,6	10	60	23,14 €
BAB10-60/P/SS	33	10	12	19	60	9	34,6	10	60	24,98 €
BAB12-25/P/SS	33	12	14,5	19	25	10	34,6	12	86	24,30 €
BAB12-30/P/SS	33	12	14,5	19	30	10	34,6	12	86	24,80 €
BAB12-35/P/SS	33	12	14,5	19	35	10	34,6	12	86	25,28 €
BAB12-40/P/SS	33	12	14,5	19	40	10	34,6	12	86	25,76 €
BAB12-45/P/SS	33	12	14,5	19	45	10	34,6	12	86	26,25 €
BAB12-50/P/SS	33	12	14,5	19	50	10	34,6	12	86	27,23 €
BAB12-60/P/SS	33	12	14,5	19	60	10	34,6	12	86	29,25 €
BAB12-70/P/SS	33	12	14,5	19	70	10	34,6	12	86	31,33 €
BAB12-80/P/SS	33	12	14,5	19	80	10	34,6	12	86	33,52 €
BAB16-30/P/SS	33	16	19	20	30	13,3	34,6	16	153	63,27 €
BAB16-35/P/SS	33	16	19	20	35	13,3	34,6	16	153	63,67 €
BAB16-40/P/SS	33	16	19	20	40	13,3	34,6	16	153	64,11 €
BAB16-45/P/SS	33	16	19	20	45	13,3	34,6	16	153	65,77 €
BAB16-50/P/SS	33	16	19	20	50	13,3	34,6	16	153	67,58 €
BAB16-60/P/SS	33	16	19	20	60	13,3	34,6	16	153	70,06 €
BAB16-70/P/SS	33	16	19	20	70	13,3	34,6	16	153	73,41 €
BAB16-80/P/SS	33	16	19	20	80	13,3	34,6	16	153	76,72 €

Dimensions in mm

Altri prodotti...



RBNpl
Ruota fissa con
piastra, Acciaio -
caucciù



ESCON
Accessori per
variatore di velocità
5A, Cavo USB per
connessione PC



PCS25ECO
Pignone a catena -
acciaio, 6.35mm



SH0
Ingranaggio elicoidale
ad assi paralleli,
Acciaio 20NCD2




BOX-CS
Fascette di serraggio,
Valigetta di fascette
acciaio



DOMI50
Accessori di
collegamento, Kit di
fissaggio



SSB
Ingranaggio conico
inox, 1:1

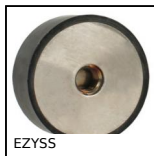

EZYSS
Piedino antivibrante
cilindrico inox, inox



SDCss
Boccole di
posizionamento per
pistoncino a molla,



MBEX
Riduttore manuale,
Manovella estremità
esagonale



CSS
Snodo sferico,
acciaio/acciaio
autolubrificante



BOX-SHNA
Dado esagonale -
DIN934, Valigetta di
dadi acciaio

Prodotti correlati



CDR
Per perno
autobloccante, Cavo
di ritegno



BABS303
Perno autobloccante
inox 303, Inox 303