

301 Stainless steel clamping pin

Sta

BABPSS

Recessed button

- Self locking

- Materials:

Body: Stainless steel 303, natural finish

Spring: Stainless steel 301

Pin: Stainless steel


- Max working temp: 250°C

Advantages

- Handle shape protects button to prevent any inadvertent operation
- Press to unlock
- Quick to insert, block, change and stop
- Simply and easily released when performing repetitive operations
- Corrosion resistant

Accessory

- CDR retaining cable (tome 1 p.39)

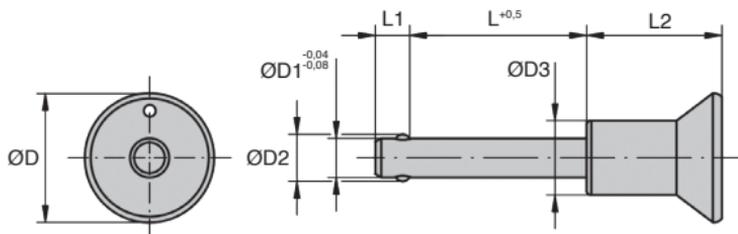

DISCOUNTS

Qty	1+	6+	10+
Disc. List	-5%	-5%	On request

Part number	ØD	ØD1	ØD2	ØD3	L	L1	L2	For bore H11	Double shear resistance (kN)	Price each 1 to 5
BAB5-10/P/SS	25	5	5,5	14	10	6	26,5	5	15	20,48 €
BAB5-15/P/SS	25	5	5,5	14	15	6	26,5	5	15	20,86 €
BAB5-20/P/SS	25	5	5,5	14	20	6	26,5	5	15	21,26 €
BAB5-25/P/SS	25	5	5,5	14	25	6	26,5	5	15	22,84 €
BAB5-30/P/SS	25	5	5,5	14	30	6	26,5	5	15	23,13 €

Dimensions in mm

Part number	ØD	ØD1	ØD2	ØD3	L	L1	L2	For bore H11	Double shear resistance (kN)	Price each 1 to 5
BAB6-10/P/SS	25	6	6,85	14	10	7	26,5	6	22	21,82 €
BAB6-15/P/SS	25	6	6,85	14	15	7	26,5	6	22	22,55 €
BAB6-20/P/SS	25	6	6,85	14	20	7	26,5	6	22	23,08 €
BAB6-25/P/SS	25	6	6,85	14	25	7	26,5	6	22	23,57 €
BAB6-30/P/SS	25	6	6,85	14	30	7	26,5	6	22	24,45 €
BAB6-35/P/SS	25	6	6,85	14	35	7	26,5	6	22	25,07 €
BAB6-40/P/SS	25	6	6,85	14	40	7	26,5	6	22	25,57 €
BAB6-45/P/SS	25	6	6,85	14	45	7	26,5	6	22	26,73 €
BAB6-50/P/SS	25	6	6,85	14	50	7	26,5	6	22	27,33 €
BAB8-20/P/SS	25	8	9,5	14	20	8	26,5	8	38	23,30 €
BAB8-25/P/SS	25	8	9,5	14	25	8	26,5	8	38	23,79 €
BAB8-30/P/SS	25	8	9,5	14	30	8	26,5	8	38	24,27 €
BAB8-35/P/SS	25	8	9,5	14	35	8	26,5	8	38	24,75 €
BAB8-40/P/SS	25	8	9,5	14	40	8	26,5	8	38	25,24 €
BAB8-45/P/SS	25	8	9,5	14	45	8	26,5	8	38	25,73 €
BAB8-50/P/SS	25	8	9,5	14	50	8	26,5	8	38	26,24 €
BAB10-20/P/SS	33	10	12	19	20	9	34,6	10	60	24,89 €
BAB10-25/P/SS	33	10	12	19	25	9	34,6	10	60	25,18 €
BAB10-30/P/SS	33	10	12	19	30	9	34,6	10	60	25,67 €
BAB10-35/P/SS	33	10	12	19	35	9	34,6	10	60	26,19 €
BAB10-40/P/SS	33	10	12	19	40	9	34,6	10	60	26,59 €
BAB10-45/P/SS	33	10	12	19	45	9	34,6	10	60	27,01 €
BAB10-50/P/SS	33	10	12	19	50	9	34,6	10	60	28,96 €
BAB10-60/P/SS	33	10	12	19	60	9	34,6	10	60	31,24 €
BAB12-25/P/SS	33	12	14,5	19	25	10	34,6	12	86	30,40 €
BAB12-30/P/SS	33	12	14,5	19	30	10	34,6	12	86	31,04 €
BAB12-35/P/SS	33	12	14,5	19	35	10	34,6	12	86	31,62 €
BAB12-40/P/SS	33	12	14,5	19	40	10	34,6	12	86	32,23 €
BAB12-45/P/SS	33	12	14,5	19	45	10	34,6	12	86	32,87 €
BAB12-50/P/SS	33	12	14,5	19	50	10	34,6	12	86	34,08 €
BAB12-60/P/SS	33	12	14,5	19	60	10	34,6	12	86	36,59 €
BAB12-70/P/SS	33	12	14,5	19	70	10	34,6	12	86	39,21 €
BAB12-80/P/SS	33	12	14,5	19	80	10	34,6	12	86	41,98 €
BAB16-30/P/SS	33	16	19	20	30	13,3	34,6	16	153	79,23 €
BAB16-35/P/SS	33	16	19	20	35	13,3	34,6	16	153	79,72 €
BAB16-40/P/SS	33	16	19	20	40	13,3	34,6	16	153	80,27 €
BAB16-45/P/SS	33	16	19	20	45	13,3	34,6	16	153	82,33 €
BAB16-50/P/SS	33	16	19	20	50	13,3	34,6	16	153	84,62 €
BAB16-60/P/SS	33	16	19	20	60	13,3	34,6	16	153	87,74 €
BAB16-70/P/SS	33	16	19	20	70	13,3	34,6	16	153	91,94 €
BAB16-80/P/SS	33	16	19	20	80	13,3	34,6	16	153	96,07 €

Dimensions in mm