



Storage bin for aluminium profile

For 8 and 10mm slots

BAC110

- **Sorting or storage bin for 40/45mm wide profiles (Type PRF4545)**

- The adjustable support can swivel +/- 45°

- With locking screw to prevent pivoting

- Materials:

Tray: Glass fibre reinforced PA plastic

Cardboard label 250g/m²

PC plastic window

Swivel hook:


Glass fibre reinforced PA plastic

Steel and Zamak fittings



Info.

- The adjustable support must be used to attach the bin in the profile slot

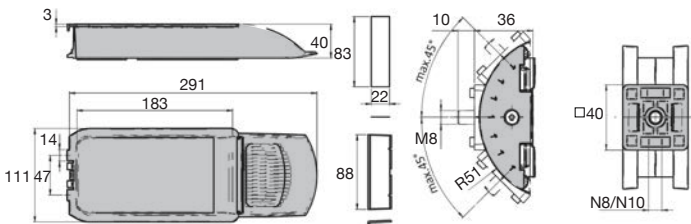

DISCOUNTS

Qty	1+	50+	100+
Disc. Net	-5%	On request	

Part N°	Colour	Weight (g)	Quantity per pack	Price each
Bin				
BAC110-270N	Black	219,3	10	11,26 €
Adjustable support				
BAC110-ACC	Black	90,8	10	8,76 €

Altri prodotti...



BOXsap

Box kit di spine elastiche ISO8752, Box kit - elastica cilindrica IS...



CHMR110

Riduttore a ruota e vite senza fine, fino a 980 Nm



CHAE4080PA

Cerniera ad avvitare estetica simmetrica, Poliammide



SSE

Snodo sferico inox, Inox/PTFE



WS20

Binario Drylin® W, Binario



BIM

Pistoncino a molla, miniatura



ARTE

Silent block, Carico multidirezionale



BAGO

Anello di bloccaggio, Acciaio



RTE

Rotex®, elastico, ghyse



SRG

Chiusura a leva regolabile, Corsa da 78mm a 90mm



PCS50

Pignone a catena - acciaio, 12.7mm (DIN08B-1)



LC

Limitatore di coppia ad attrito, 30 a 240 Nm

Prodotti correlati



BAC110

Contenitore a becco, Contenitore



PRF1932

Profilato alluminio standard, 19 x 32 mm



PRF4545

Profilato alluminio standard, 45 x 45 mm



PRF4590

Profilato alluminio standard, 45 x 90 mm