

# Split shaft collar with clamp lever

## BAG-MI

## Steel

- Ensures a uniform distribution of the clamping force
- Clamps securely to any type of shaft
- Material:

Burnished steel (S250Pb)

Repeated operations

 



### Advantages

- Fits perfectly on to the shaft with a high clamping force but without risk of damage

### Info.

- Recommended shaft tolerance: h11

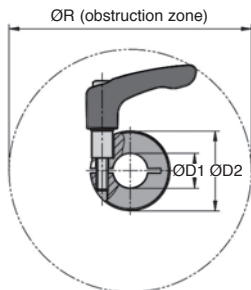

### DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-15%	-20%	On request

Part number	ØD1	ØD2	B	ØR	Stock*	Price each 1 to 5
BAG1-010-MI	10	24	9	44,1	-	14,83 €
BAG1-012-MI	12	28	11	90,4	✓	15,16 €
BAG1-015-MI	15	34	13	105,0	-	16,38 €
BAG1-016-MI	16	34	13	105,0	✓	16,73 €
BAG1-018-MI	18	36	13	105,7	-	17,46 €
BAG1-020-MI	20	40	15	103,8	✓	18,26 €
BAG1-022-MI	22	42	15	104,2	-	18,26 €
BAG1-025-MI	25	45	15	104,8	✓	19,34 €
BAG1-028-MI	28	48	15	106,8	-	19,34 €
BAG1-030-MI	30	54	15	112,6	✓	22,20 €
BAG1-040-MI	40	60	15	113,2	-	25,18 €
BAG1-050-MI	50	78	19	150,2	-	46,79 €

Dimensions in mm

## Altri prodotti...



WS20  
Binario Drylin® W,  
Binario



PPG  
Pistoncino a molla,  
Con flangia di  
fissaggio orizzontale



PPD  
Pistoncino a molla,  
Per lamiera




gt64  
Chiusura a farfalla,  
Tolleranze di  
montaggio normali



SBF  
Sealed flange bearing  
unit for Food Industry,  
cover



GALRUB  
Rullo per  
trasportatore, Caucciù

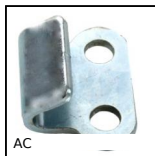

AC  
Piastrina di riscontro,  
18mm



PFC  
Piede fisso,  
Livellamento per  
piccoli elementi



ACL  
Elementi di giunzione,  
Angolare  
semicircolare



LRR  
Chiavistello con perno  
prismatico, Gancio



GB-RA  
Ingranaggio dritto  
ottone, Ottone  
CuZn39Pb3



M0  
Coppia ruota e vite  
senza fine, Acciaio  
non temprato

## Prodotti correlati



BAG-MISS  
Anello di serraggio  
con intaglio e  
maniglia a leva, Inox



BAG  
Anello di bloccaggio in  
acciaio, Acciaio