

Split shaft collar with clamp lever

BAG-MI

Steel

- Ensures a uniform distribution of the clamping force
- Clamps securely to any type of shaft
- Material:

Burnished steel (S250Pb)

Repeated operations

 



Advantages

- Fits perfectly on to the shaft with a high clamping force but without risk of damage

Info.

- Recommended shaft tolerance: h11

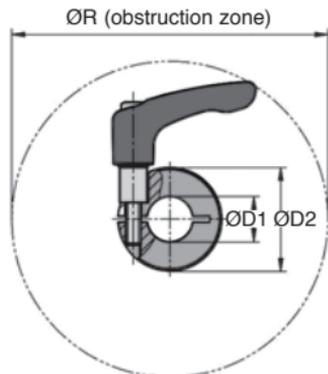

DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-15%	-20%	On request

Part number	ØD1	ØD2	B	ØR	Stock*	Price each 1 to 5
BAG1-010-MI	10	24	9	44,1	-	14,83 €
BAG1-012-MI	12	28	11	90,4	✓	15,16 €
BAG1-015-MI	15	34	13	105,0	-	16,38 €
BAG1-016-MI	16	34	13	105,0	✓	16,73 €
BAG1-018-MI	18	36	13	105,7	-	17,46 €
BAG1-020-MI	20	40	15	103,8	✓	18,26 €
BAG1-022-MI	22	42	15	104,2	-	18,26 €
BAG1-025-MI	25	45	15	104,8	✓	19,34 €
BAG1-028-MI	28	48	15	106,8	-	19,34 €
BAG1-030-MI	30	54	15	112,6	✓	22,20 €
BAG1-040-MI	40	60	15	113,2	-	25,18 €
BAG1-050-MI	50	78	19	150,2	-	46,79 €


Dimensions in mm

Altri prodotti...



TBE12

Economic mini-table with trapezoidal leadscrew, 2kg

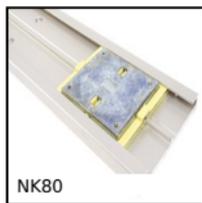

NK80

Guida mini Drylin® N, Larghezza 80mm



MSP23

Inserto con piastrina a incollare Masterplate®, Cilindrico Ø23 con...



CHA225

Cerniera ad avvitare, 225 gradi



T10_21_AL

Puleggia dentata di posizionamento tipo T, Serie economica - T10 all...



NTM

Grano punta in nylon, punta in nylon



PR123rehausse

Extension for articulated foot Ø123, Ø 123



PSG05S

Ingranaggio dritto di precisione, Inox 316



WBGV

Anello di sollevamento, Con



DOMI80

Slitta di regolazione Domino 80, Slitta



RHTplss

Ruota alte temperature, fino a



CRM

Cremagliera in nylon stampato, Nylon

Prodotti correlati



BAG-MISS

Anello di serraggio con intaglio e maniglia a leva, Inox



BAG

Anello di bloccaggio in acciaio, Acciaio