

Split shaft collar with clamp lever

Stainless steel

BAG-MI/SS

Repeated operations


- Ensures a uniform distribution of the clamping force
- Clamps securely to any type of shaft
- Material:
Polished stainless steel (303)

Advantages

- Fits perfectly on to the shaft with a high clamping force but without risk of damage

Info.

- Recommended shaft tolerance: h11

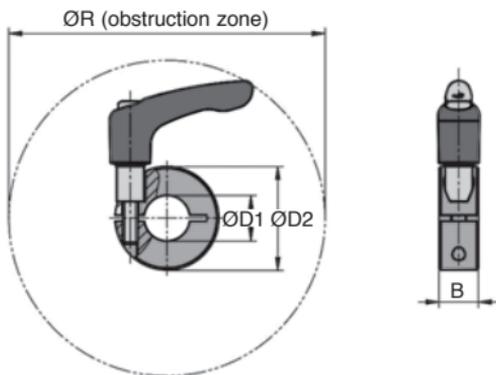

DISCOUNTS

Qty	1+	6+	40+
Disc.	List	-15%	On request

Part number	ØD1	ØD2	B	ØR	Stock*	Price each 1 to 5
BAG1-010-MI/SS	10	24	9	44,1	✓	21,60 €
BAG1-012-MI/SS	12	28	11	90,4	-	21,93 €
BAG1-015-MI/SS	15	34	13	105,0	✓	25,63 €
BAG1-016-MI/SS	16	34	13	105,0	✓	25,91 €
BAG1-018-MI/SS	18	36	13	105,7	-	28,61 €
BAG1-020-MI/SS	20	40	15	103,8	✓	33,16 €
BAG1-022-MI/SS	22	42	15	104,2	-	34,05 €
BAG1-025-MI/SS	25	45	15	104,8	✓	34,95 €
BAG1-028-MI/SS	28	48	15	106,8	-	36,74 €
BAG1-030-MI/SS	30	54	15	112,6	✓	38,53 €
BAG1-040-MI/SS	40	60	15	113,2	✓	53,49 €
BAG1-050-MI/SS	50	78	19	150,2	-	106,10 €

Dimensions in mm

0 825 88 6000
Service 0,15 € / min
+ prix appel

Fax

cial2@hpceurope.com

HPC

SUPPLEMENT 2019

113

Altri prodotti...



PF20

Riduttore a ruota e vite senza fine, fino a 5 Nm



GE14

Chiusura a leva, Con porta-lucchetto



MAC

Moschettone DIN5299 acciaio, Acciaio



BMM

Manopola, zigrinata



LC

Limitatore di coppia ad attrito, 190 a 1800 Nm



PCS50SS

Pignone a catena - Inox, 12.7mm (DIN 08B-1)



TUBE25_25

Tubo quadrato, Alluminio



PRF_GAL

Rotella per profilo alluminio, Kit di fissaggio per rotella eccentrica




HW_HT

Guida su semi-binari, Binario



WS10

Guida modulabile Drylin® W, Binario

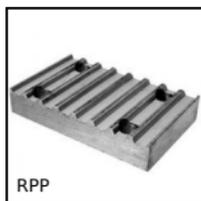

RPP

Piastra di giunzione per cinghia RPP,



RAM35

Riduttore manuale, Rinvio angolare

Prodotti correlati



BAG-MI

Anello di serraggio con intaglio e maniglia a leva, Acciaio



BAGSS

Anello di bloccaggio inox, Inox