

Split shaft collar with clamp lever

Stainless steel

BAG-MI/SS

Repeated operations


- Ensures a uniform distribution of the clamping force
- Clamps securely to any type of shaft
- Material:
Polished stainless steel (303)

Advantages

- Fits perfectly on to the shaft with a high clamping force but without risk of damage

Info.

- Recommended shaft tolerance: h11

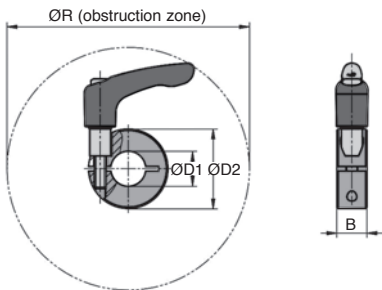

DISCOUNTS

Qty	1+	6+	40+
Disc.	List	-15%	On request

Part number	ØD1	ØD2	B	ØR	Stock*	Price each 1 to 5
BAG1-010-MI/SS	10	24	9	44,1	✓	21,60 €
BAG1-012-MI/SS	12	28	11	90,4	-	21,93 €
BAG1-015-MI/SS	15	34	13	105,0	✓	25,63 €
BAG1-016-MI/SS	16	34	13	105,0	✓	25,91 €
BAG1-018-MI/SS	18	36	13	105,7	-	28,61 €
BAG1-020-MI/SS	20	40	15	103,8	✓	33,16 €
BAG1-022-MI/SS	22	42	15	104,2	-	34,05 €
BAG1-025-MI/SS	25	45	15	104,8	✓	34,95 €
BAG1-028-MI/SS	28	48	15	106,8	-	36,74 €
BAG1-030-MI/SS	30	54	15	112,6	✓	38,53 €
BAG1-040-MI/SS	40	60	15	113,2	✓	53,49 €
BAG1-050-MI/SS	50	78	19	150,2	-	106,10 €

Dimensions in mm

0 825 88 6000
Service 0,15 € / min
+ prix appel

Fax

cial2@hpceurope.com

HPC

SUPPLEMENT 2019

113

Altri prodotti...



PRF-SRA
Sistema di chiusura
per profili alluminio,
Serrata




BLHT70
Rinvio angolare a T,
da 26 a 128 Nm



NTM
Grano punta in nylon,
punta in nylon



MHX
Manicotto esagonale
maschiato, Esagonale
- inox

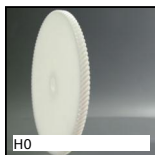


H0
Ingranaggio elicoidale
ad assi incrociati a
90°, Plastica lavorata
...



OPFL_OPPM
Accessorio per
indicatori, Pomello di
manovra



S_2RS
Cuscinetto radiale a
sfere, Inox

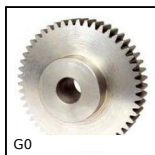

G0
Ingranaggio dritto
acciaio, Acciaio
20NCD2



NPTF30
Morsetto di
collegamento, Fisso
Ø14 a Ø20



NCT
Giunto di
collegamento, Ad
angolo fisso



SSHBRA
Ingranaggio conico
inox, 1,5:1 2:1 3:1



LVT
Mini martinetto
motorizzato 4A, 4
ampere

Prodotti correlati



BAG-MI
Anello di serraggio
con intaglio e
maniglia a leva,
Acciaio



BAGSS
Anello di bloccaggio
inox, Inox