

Split shaft collar with clamp lever

Stainless steel

BAG-MI/SS

Repeated operations

- Ensures a uniform distribution of the clamping force
- Clamps securely to any type of shaft
- Material:
Polished stainless steel (303)


Advantages

- Fits perfectly on to the shaft with a high clamping force but without risk of damage

Info.

- Recommended shaft tolerance: h11

stainless steel

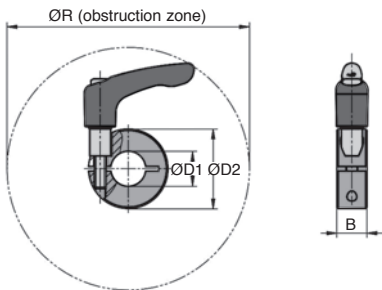

DISCOUNTS

Qty	1+	6+	40+
Disc.	List	-15%	On request

Part number	ØD1	ØD2	B	ØR	Stock*	Price each 1 to 5
BAG1-010-MI/SS	10	24	9	44,1	✓	21,60 €
BAG1-012-MI/SS	12	28	11	90,4	-	21,93 €
BAG1-015-MI/SS	15	34	13	105,0	✓	25,63 €
BAG1-016-MI/SS	16	34	13	105,0	✓	25,91 €
BAG1-018-MI/SS	18	36	13	105,7	-	28,61 €
BAG1-020-MI/SS	20	40	15	103,8	✓	33,16 €
BAG1-022-MI/SS	22	42	15	104,2	-	34,05 €
BAG1-025-MI/SS	25	45	15	104,8	✓	34,95 €
BAG1-028-MI/SS	28	48	15	106,8	-	36,74 €
BAG1-030-MI/SS	30	54	15	112,6	✓	38,53 €
BAG1-040-MI/SS	40	60	15	113,2	✓	53,49 €
BAG1-050-MI/SS	50	78	19	150,2	-	106,10 €

Dimensions in mm

0 825 88 6000

Service 0,15 € / min
+ prix appel

Fax

cial2@hpceurope.com

HPC

SUPPLEMENT 2019

113

Altri prodotti...



LF

Cuscinetti a sfere -
Accessorio, Ghiera di
regolazione



PPRss

Piastrina con anello,
Inox



PCS_PA6

, 9,525mm (DIN
06B-1)



PW_PWG3

Vite senza fine di
precisione, Inox



CHAR6035

Cerniera a molla,
avvitabile e saldabile




MHWC

Giunto flessibile a
dischi doppi, Disco
doppio



PMC48_M8

Supporto antivibrante
a campana, Piastra a
base ovale

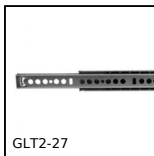

GLT-27

Guide telescopiche
per montaggio in
scanalatura,
Estensione parziale



SLB

Pistoncino a molla,
acciaio classe 5.8



SCA_SS

Serracavo, Inox



G0

Ingranaggio dritto
acciaio, Acciaio
20NCD2



FF20

Riduttore ad alberi
paralleli, da 5.80 a 23
Nm

Prodotti correlati



BAG-MI

Anello di serraggio
con intaglio e
maniglia a leva,
Acciaio



BAGSS

Anello di bloccaggio
inox, Inox