

Mushroom knob with male thread and high head

BCFHUSS

Hygienic Usit®


- **Mushroom knob with a male thread and high head for use with Hygienic Usit® sealing washers**®
- The high head makes this mushroom knob ideal for manual lateral movements.
- Fully polished surface with a roughness much lower than Ra0.8µm.
- Material:
Stainless steel 1.4404 (316L)
Mirror polished finish

Advantages

- Regardless of the mounting position of the mushroom knob, dirt and residue from product or cleaning material will not adhere. This guarantees easy cleaning.
- USIT® Hygienic sealing washers are used to seal the screwed connection.
- The stem of the mushroom knob is specially designed to ensure an almost cavity free seal thus meeting hygiene requirements.

Accessory

- RDE sealing washers (see pages 37 à 39)

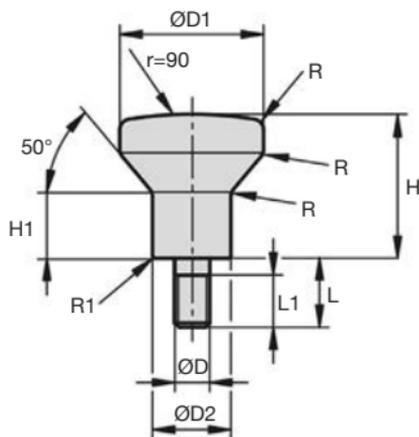

DISCOUNTS

| Qty | 1+ | 6+ | 10+ | 25+ |
|-------|------|-----|------|------------|
| Disc. | Prix | -5% | -10% | On request |

| Part N° | ØD | ØD1 | ØD2 | H | H1 | L | T | R | R1 | Price each |
|--------------|-----|-----|------|----|----|----|----|---|------|------------|
| | | | | | | | | | | 1 to 4 |
| BCFH-4/HUSS | M4 | 20 | 10,8 | 19 | 8 | 8 | 7 | 3 | 0,45 | 13,02 € |
| BCFH-5/HUSS | M5 | 21 | 11,8 | 21 | 10 | 10 | 9 | 3 | 0,50 | 14,10 € |
| BCFH-6/HUSS | M6 | 25 | 14,2 | 25 | 12 | 12 | 11 | 3 | 0,55 | 15,68 € |
| BCFH-8/HUSS | M8 | 33 | 18,0 | 33 | 15 | 16 | 15 | 4 | 0,60 | 26,40 € |
| BCFH-10/HUSS | M10 | 40 | 22,3 | 40 | 19 | 20 | 19 | 4 | 0,75 | 28,18 € |

All dimensions in mm

Altri prodotti...



BCFH

Pomello a fungo Hygienic Usit®, Con perno filettato e collare alto



LACT_SS

Leva a camma regolabile, Maschio



PP50

Riduttore a ruota e vite senza fine, da 6.50 a 12.80 Nm



MDB_MTB

Ingranaggio conico in plastica stampata , 2:1



PRF-SCREEN-5

Screen support, Support with 5 axes of rotation



SVG

Chiusura a leva regolabile, Corsa da 82mm a 92mm



ZBconique

Ingranaggio conico in plastica, 1:1



M0

Vite senza fine , Acciaio non temprato



NT62

Riduttore coassiale a treni paralleli, da 6 a 18 Nm - a treni



ZDB

Ingranaggio conico in plastica, 2:1



MLY


Grillo con chiodo ad occhiello, Acciaio



H1

Ingranaggio elicoidale ad assi incrociati a 90°, Acciaio 20NCD2

Prodotti correlati

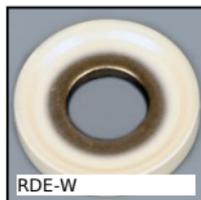

RDE-W

Rondella di tenuta Hygienic Usit®, Inox - EPDM bianco



RDE-B

Rondella di tenuta Hygienic Usit®, Stainless steel - EPDM blu



BCTH

Pomello a fungo Hygienic Usit®, Con foro filettato e collare alto