



Mushroom knob with female thread and high head

Hygienic Usit®

BCTH_{HUSS}

- **Mushroom knob with a female thread and high head for use with Hygienic Usit® sealing washers**
- The high head makes this mushroom knob ideal for manual lateral movements.
- Fully polished surface with a roughness much lower than Ra0.8µm.
- Material:
Stainless steel 1.4404 (316L)
Mirror polished finish




Advantages

- Regardless of the mounting position of the mushroom knob, dirt and residue from product or cleaning material will not adhere. This guarantees easy cleaning.
- USIT® Hygienic sealing washers are used to seal the screwed connection.
- The base of the mushroom knob is designed to ensure an almost cavity free seal thus meeting hygiene requirements.

Accessory

- RDE sealing washers (see pages 37-39)

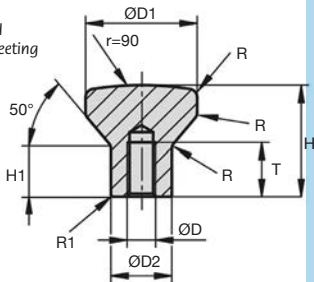

DISCOUNTS

Qty	1+	6+	10+	25+
Disc.	Net	-5%	-10%	On request

Part N°	ØD	ØD1	ØD2	H	H1	T	R	R1	Price each
									1 to 4
BCTH-4/HUSS	M4	20	10,8	19	8	10	3	0,45	10,84 €
BCTH-5/HUSS	M5	21	11,8	21	10	12	3	0,50	11,74 €
BCTH-6/HUSS	M6	25	14,2	25	12	12	3	0,55	13,07 €
BCTH-8/HUSS	M8	33	18,0	33	15	16	4	0,60	22,01 €
BCTH-10/HUSS	M10	40	22,3	40	19	20	4	0,75	23,47 €

All dimensions in mm

Fax 0 825 88 6000
Service 0,15 €/min
+ prix appel

cial2@hpceurope.com

HPC SUPPLEMENT 2019

Altri prodotti...



GLT3-76

Guide telescopiche acciaio, Estensione totale




PRF1932

Profilato alluminio standard, 19 x 32 mm



G0

Ingranaggio dritto acciaio, Acciaio 20NCD2

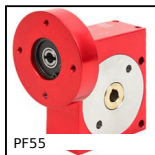

PF55

Riduttore a ruota e vite senza fine, fino a 57 Nm



RFK58B

Riduttore ipoide inox, fino a 500 Nm



ABL100005

Spazzola antistatica, Standard



CHMBR

Braccio di reazione, Braccio di reazione per riduttori CHM e CHMR




TAC

Tenditore, Acciaio




ACLERP

Rulliera, Con guida laterale

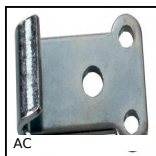

AC

Piastrina di riscontro, 15mm

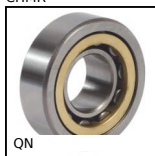

QN

Cuscinetto a singola corona di rulli cilindrici, Anello



PTA40

Articulated foot with solid base foot \varnothing 40, 30000N

Prodotti correlati



RDE-W

Rondella di tenuta Hygienic Usit®, Inox - EPDM bianco



RDE-B

Rondella di tenuta Hygienic Usit®, Stainless steel - EPDM blu



BCFH

Pomello a fungo Hygienic Usit®, Con perno filettato e collare alto