


- **Universal rigid support arm , adjustable**

- Material :


Aluminium with steel screws

### Advantages

- Securely supports gripping jaws
- Flexible mounting possibilities
- Angle adjustable over full range, blocked in position using M6 screw

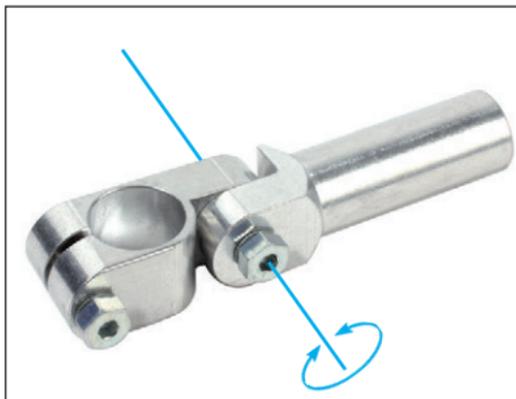

**NEW!**

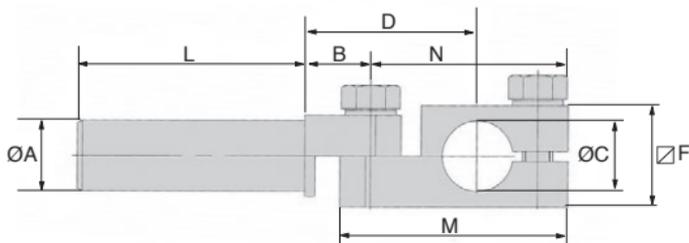

### DISCOUNTS

Qty	1+	10+	30+
Disc.	List	-5%	On request

Part number	ØA	B	ØC	D	L	M	ØF	N	Weight (g)	Price each 1 to 9
BDP20-50/1R	20	15	20	36	50	49	25	43	87	51,56 €
BDP20-100/1R	20	15	20	36	100	49	25	43	103	56,69 €
BDP20-150/1R	20	15	20	36	150	49	25	43	120	57,21 €

Dimensions in mm

## Altri prodotti...



PRF3232

Profilato alluminio standard, 32 x 32 mm



MSP19

Inserto con piastrina a incollare Masterplate®, Cilindrico con dado




YGO

Ingranaggio dritto PRESTAZIONE, Acciaio 35NCD6



PF40NM

Riduttore a ruota e vite senza fine, fino a 18 Nm

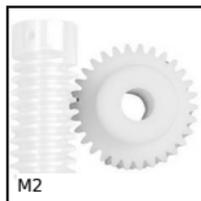

M2

Coppia ruota e vite senza fine, Plastica lavorata (delrin)



HAR9

Rondella girevole, DIN 6371



UGH16

Unità di guida tipo H, Per martinetti Ø12 e Ø16



PITAss

Pistoncino a molla, con maniglia a T



HD

Giunto cardanico doppio ad aghi,



UTKpwc

Guida lineare Utilitrack®, Ruota a V



VPR

Vite ad alette Hygienic Usit®, Inox



NPTR

Morsetto, Regolabile

## Prodotti correlati



BDP2R

Braccio di reazione, Serraggio rinforzato



BDPR

Braccio di reazione, Rigido