


- **Universal rigid support arm , adjustable**

- Material :


Aluminium with steel screws

Advantages

- Securely supports gripping jaws
- Flexible mounting possibilities
- Angle adjustable over full range, blocked in position using M6 screw

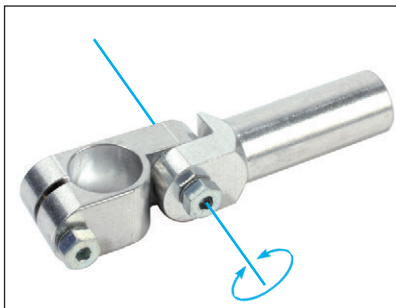

NEW!

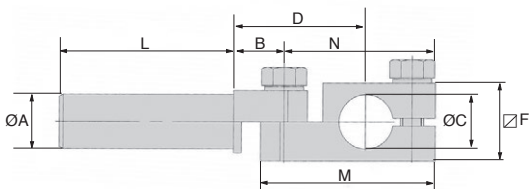

DISCOUNTS

Qty	1+	10+	30+
Disc.	List	-5%	On request

Part number	ØA	B	ØC	D	L	M	ØF	N	Weight (g)	Price each 1 to 9
BDP20-50/1R	20	15	20	36	50	49	25	43	87	51,56 €
BDP20-100/1R	20	15	20	36	100	49	25	43	103	56,69 €
BDP20-150/1R	20	15	20	36	150	49	25	43	120	57,21 €

Dimensions in mm

Altri prodotti...



LWH

Guida lineare a sfere -
Sfere acciaio, Binario -
da 9320 N a 71300 N



CDR

Per perno
autobloccante, Cavo
di ritengo



CHAsb63

Cerniera senza perno,
Cerniera in polimero



BCM_HPBT

Spazzola cilindrica
modulare, Filo
poliestere PBT



SVG

Chiusura a leva
regolabile, Corsa da
118mm a 130,5mm



ZBconique

Ingranaggio conico in
plastica, 1:1



R206

Molla per stampi
ISO10243, Extra-forte



PRF_JL6

Panel accessories,
Guarnizione - Ø 6mm



VTSM

Ball head screws
Hygienic Design®,
Inox



UGAC_UGET

Guida per cilindrico,
Ghiera per stelo
filettato del



ES

Bipod support base,
Plastic



SVT5

Martinetto a vite - Vite
traslante, Vite
traslante

Prodotti correlati



BDP2R

Braccio di reazione,
Serraggio rinforzato



BDPR

Braccio di reazione,
Rigido