


- **Universal rigid support arm , adjustable**

- Material :


Aluminium with steel screws

Advantages

- Securely supports gripping jaws
- Flexible mounting possibilities
- Angle adjustable over full range, blocked in position using M6 screw

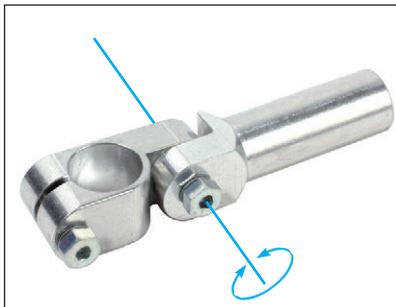

NEW!

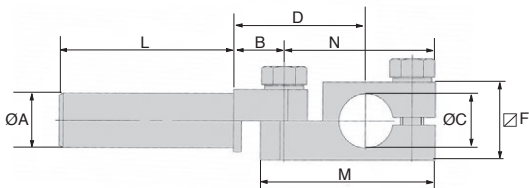

DISCOUNTS

Qty	1+	10+	30+
Disc.	List	-5%	On request

Part number	ØA	B	ØC	D	L	M	ØF	N	Weight (g)	Price each 1 to 9
BDP20-50/1R	20	15	20	36	50	49	25	43	87	51,56 €
BDP20-100/1R	20	15	20	36	100	49	25	43	103	56,69 €
BDP20-150/1R	20	15	20	36	150	49	25	43	120	57,21 €

Dimensions in mm

Altri prodotti...



PDM_PDV
Detectable plastic
palm grip, blue
thermoplastic




BEAS
Manopola, stella,
antistatico




UCFL_SS
Cuscinetto a flangia
ovale tutto inox, Inox



AT5M AT10M
Cinghia aperta al
metro tipo AT, AT5
Poliuretano armatura
in acciaio

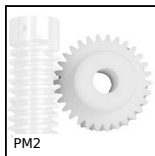

PM2
Ruota per vite senza
fine, Plastica lavorata
(delrin)

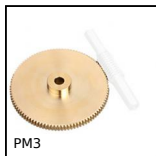

PM3
Ruota per vite senza
fine, Bronzo




RAS
Snodo angolare a 90°
DIN71802, Inox



CHARcav
Cerniera a molla, to
install



GLT3E-50
Guide telescopiche
acciaio, Estensione
extra

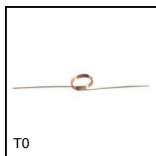

T0
Molla di torsione, Inox



UCF_SS
Cuscinetto a flangia
quadrata tutto inox,
Inox



BDM
Perno ad innesto per
boccia magnetica,
Bloccaggio magnetico
rapido ...

Prodotti correlati



BDP2R
Braccio di reazione,
Serraggio rinforzato



BDPR
Braccio di reazione,
Rigido