


- **Universal rigid support arm , adjustable**

- Material :


Aluminium with steel screws

### Advantages

- Securely supports gripping jaws
- Flexible mounting possibilities
- Angle adjustable over full range, blocked in position using M6 screw

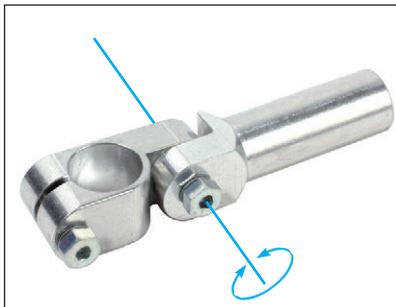

**NEW!**

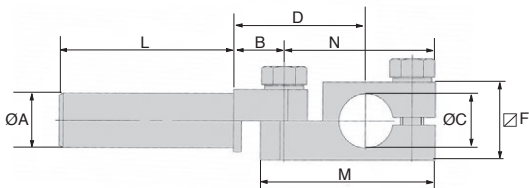

### DISCOUNTS

Qty	1+	10+	30+
Disc.	List	-5%	On request

Part number	ØA	B	ØC	D	L	M	ØF	N	Weight (g)	Price each 1 to 9
BDP20-50/1R	20	15	20	36	50	49	25	43	87	51,56 €
BDP20-100/1R	20	15	20	36	100	49	25	43	103	56,69 €
BDP20-150/1R	20	15	20	36	150	49	25	43	120	57,21 €

Dimensions in mm

## Altri prodotti...



CMM  
Testa a snodo  
maschio DIN  
ISO12240-4, Acciaio /  
bronzo



RCX-6  
Rondella sferica -  
DIN6319, convessa



BH01  
Cuscinetto radiale  
flangiato, Montaggio :  
pressione e colla



PCP  
Kit connettori per  
portacelle, Pre-  
assemblato



METC  
Cuscinetto a collare ,  
Bronzo  
autolubrificante  
METAFRAM



CSS  
Snodo sferico,  
acciaio/acciaio  
autolubrificante



PCS50  
Pignone a catena -  
acciaio, 12.7mm  
(DIN08B-1)



CHAR5050\_Z  
Cerniera a molla,  
avvitabile



PTKFss  
Piede fissabile  
speciale  
agroalimentare,



HG8-ECO  
Ingranaggio dritto  
acciaio, Acciaio C45



PRF-SCREEN-4  
Screen support,  
Support with 4 axes of  
rotation



LINK64  
Motoriduttore AC  
sincrono, da 1.3 a  
6Nm

## Prodotti correlati



BDP2R  
Braccio di reazione,  
Serraggio rinforzato



BDPR  
Braccio di reazione,  
Rigido