
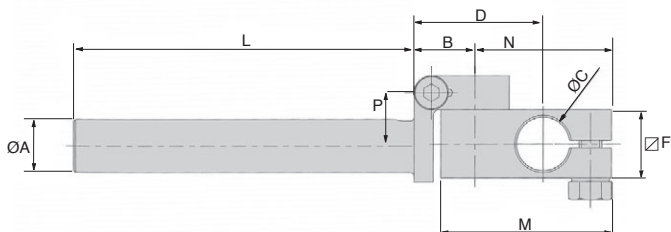


- Universal adjustable support arm, strengthened
- Material :
Aluminium with steel screws

Advantages

- Safe in operation through use of optimised jaw support

NEW!

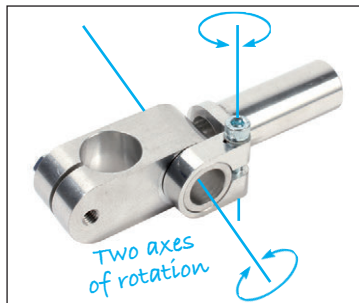

DISCOUNTS

Qty	1+	10+	30+
Disc.	List	-5%	On request

Part number	ØA	B	ØC	D	L	M	∅F	N	P	Weight (g)	Price each 1 to 9
BDP20-50/2R	20	19	20	43	50	59	24	47	16,5	89	90,27 €
BDP20-100/2R	20	19	20	43	100	59	24	47	16,5	104	95,80 €
BDP20-150/2R	20	19	20	43	150	59	24	47	16,5	119	101,32 €

Dimensions in mm

Altri prodotti...



DOG258

Motoriduttore DC 12V e 24V DC, da 12 a 15 Nm



GBS

Dado per vite a sfere, Dado flangiato



WJUM20

Pattino Drylin® W, Pattino



DB

Ingranaggio conico - Acciaio 60C40, 2:1




HTD14M_85

Puleggia dentata di trasmissione tipo HTD, HTD14 Acciaio



BLHM60

Rinvio angolare, fino a 70 Nm

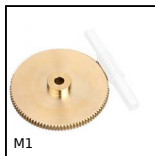


M1

Ruota per vite senza fine, Bronzo



T10_21N1F

Puleggia dentata di posizionamento tipo T, Serie economica - T10 nyl...

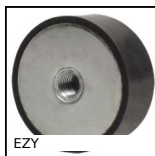

EZY

Piedino antivibrante cilindrico, Acciaio



PRF_GAL

Rotella per profilo alluminio, Kit di fissaggio per rotella



UTKpwr

Guida lineare Utilitrack®, Profilo guida a V



RPCplss

Ruota fissa con piastra, Inox - Poliammide

Prodotti correlati



BDPR

Braccio di reazione, Rigido



BDP1R

Braccio di reazione, Serraggio standard