
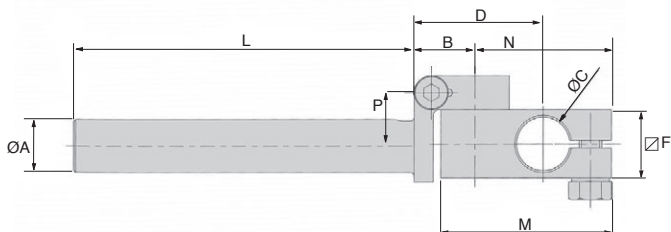


- **Universal adjustable support arm, strengthened**
- **Material :**
Aluminium with steel screws

Advantages

- Safe in operation through use of optimised jaw support

NEW!

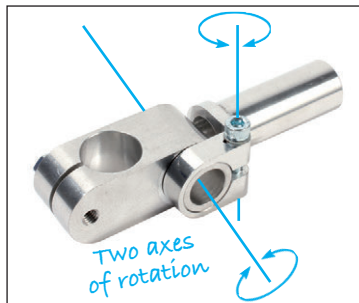

DISCOUNTS

Qty	1+	10+	30+
Disc.	List	-5%	On request

Part number	ØA	B	ØC	D	L	M	∅F	N	P	Weight (g)	Price each 1 to 9
BDP20-50/2R	20	19	20	43	50	59	24	47	16,5	89	90,27 €
BDP20-100/2R	20	19	20	43	100	59	24	47	16,5	104	95,80 €
BDP20-150/2R	20	19	20	43	150	59	24	47	16,5	119	101,32 €

Dimensions in mm

Altri prodotti...



GARDLL

Bussola portamaschi,
Acciaio o Inox
Acciaio nichelato or
Inox



CDGamme

Molla di compressione
DIN2095, DIN 2095



ACLLPP

Sistema di chiusura,
Chiusura a molla



WS10

Guida modulabile
Drylin® W, Binario



ZBRA

Ingranaggio conico in
plastica, 1:1



PSG125

Ingranaggio dritto di
precisione, Acciaio
20NCD2 cementato
temprato



BPHRF

Sfera portante, Forte



PSG155

Ingranaggio dritto di
precisione, Inox 303



AT5M AT10M

Cinghia aperta al
metro tipo AT, AT10



CHB

Riduttore a ruota e
vite senza fine, fino a



MCL

Manicotto cilindrico
maschiato, Cilindrico -



PRF_VTM

Fissaggio, Vite testa
martello

Prodotti correlati



BDPR

Braccio di reazione,
Rigido



BDP1R

Braccio di reazione,
Serraggio standard