
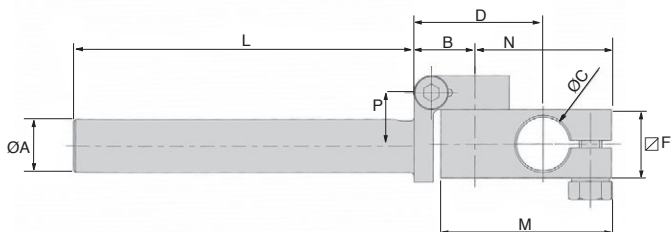


- Universal adjustable support arm, strengthened
- Material :  
Aluminium with steel screws

### Advantages

- Safe in operation through use of optimised jaw support

**NEW!**

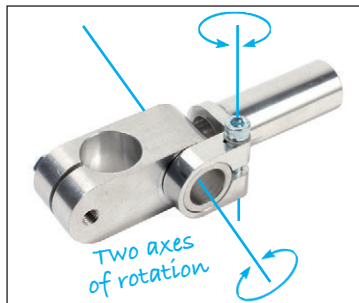

### DISCOUNTS

Qty	1+	10+	30+
Disc.	List	-5%	On request

Part number	ØA	B	ØC	D	L	M	∅F	N	P	Weight (g)	Price each 1 to 9
BDP20-50/2R	20	19	20	43	50	59	24	47	16,5	89	90,27 €
BDP20-100/2R	20	19	20	43	100	59	24	47	16,5	104	95,80 €
BDP20-150/2R	20	19	20	43	150	59	24	47	16,5	119	101,32 €

Dimensions in mm

## Altri prodotti...



HW\_HT

Guida su semi-binari,  
Binario



PRES3HR

Pressa manuale da  
banco, Pressione fino  
a 400kg



GLT2-17

Guide telescopiche  
per montaggio in  
scanalatura,  
Estensione parziale



APB\_F

Perno di fissaggio per  
morsetti, Filettato



PTA100

Piede snodato con  
base stampata Ø100,  
Ø 100



BHEX

Tappo di protezione  
esagonale,  
Tecnopolimero nero



RVM25

Riduttore manuale,  
Rinvio angolare



RPCtc

Ruota girevole a foro  
centrale, Acciaio -  
Poliammide - a doppio  
bloc...



BDPR

Braccio di reazione,  
Rigido



CHAsb89

Cerniera senza perno,  
□Cerniera in polimero



UGPL

Unità di guida per  
cilindrico, Cuscinetto  
lungo



G0

Ingranaggio dritto  
acciaio, Acciaio  
20NCD2

## Prodotti correlati



BDPR

Braccio di reazione,  
Rigido



BDP1R

Braccio di reazione,  
Serraggio standard