
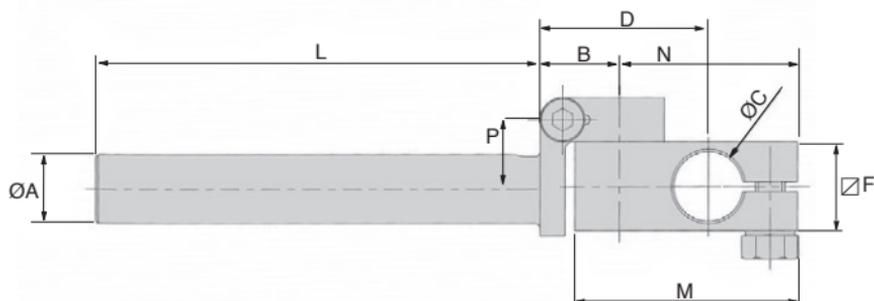


- Universal adjustable support arm, strengthened
- Material :
Aluminium with steel screws

Advantages

- Safe in operation through use of optimised jaw support

NEW!

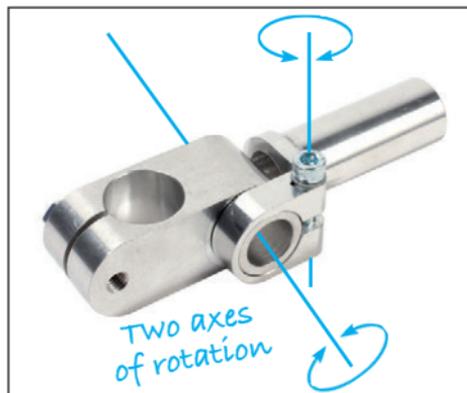

DISCOUNTS

Qty	1+	10+	30+
Disc.	List	-5%	On request

Part number	ØA	B	ØC	D	L	M	ØF	N	P	Weight (g)	Price each 1 to 9
BDP20-50/2R	20	19	20	43	50	59	24	47	16,5	89	90,27 €
BDP20-100/2R	20	19	20	43	100	59	24	47	16,5	104	95,80 €
BDP20-150/2R	20	19	20	43	150	59	24	47	16,5	119	101,32 €

Dimensions in mm

Altri prodotti...



PRES
Accessori per pressa
PRES-3HR e
PRES-4HR, Portapinzine



PCS_PA6
, 9.525mm (DIN
06B-1)



CFF_SS
Testa a snodo
femmina DIN
ISO12240-4, Inox /
bronzo - Serie



PSG08HC
Ingran. dritto di
precisione trattato
skiving, Acciaio
20NCD2 cement...



BPFss
Supporto a flangia
tonda a carico leggero
inox, Inox



HG6-ECO
Ingranaggio dritto
acciaio - serie ECO,
Acciaio C45



HBM
Guida su semi-binari,
Boccola di regolazione



M1
Vite senza fine ,
Acciaio non temprato



ACLEPP
Angolare, 8 fori



CHAFR
Cerniera, A frizione



DBL880
Rotella per catena,
Serie 880 e 881



CPAS-H
Squadra pieghevole,
Per carico pesante

Prodotti correlati



BDPR
Braccio di reazione,
Rigido



BDP1R
Braccio di reazione,
Serraggio standard